


## PowerBlade™ Cable Cutter



(Drill not included)

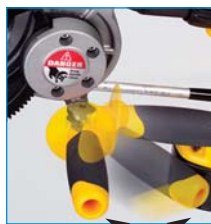

(Folding handle for storage.)

- Extremely versatile: fits almost any drill (12V minimum)
- Cuts up to 750 MCM hard - drawn copper, 1000 MCM aluminum\*
- Heavy-duty gears and specially hardened blades for professional quality
- Rounded blade design minimizes cable distortion during cutting
- No need to mess with battery packs or special chargers; this tool works with the drill you already carry!

Description	Cat. No.
PowerBlade™ Cable Cutter	<b>35-078</b>
PowerBlade™ Replacement Handle	<b>K-8947R</b>
PowerBlade™ Replacement Blades (pair)	<b>K-8906R</b>
PowerBlade™ Replacement Torque Arm Assembly	<b>K-8909</b>
PowerBlade™ Replacement Carrying Case	<b>K-8926</b>

\*Max. Jaw Opening - 2 in. Not for cutting steel or ASCR.

## Long-Arm Cable Cutters

- High strength forged blades for ultimate durability
- Precision-ground jaws make clean cuts with minimal cable distortion
- Replaceable blades
- For copper and aluminum only. Not designed for steel or ASCR.



Description	Length	Cat. No.
250 MCM Long-Arm Cable Cutter	14 in.	<b>35-031</b>
500 MCM Long-Arm Cable Cutter	22 in.	<b>35-032</b>
1000 MCM Long-Arm Cable Cutter	32 in.	<b>35-033</b>
Replacement Head – 250 MCM (for 35-031)	—	<b>35-031B</b>
Replacement Head – 500 MCM (for 35-032)	—	<b>35-032B</b>
Replacement Head – 1000 MCM (for 35-033)	—	<b>35-033B</b>

**CAUTION: Comfort-grip handles are not designed for protection against electrical shock. Do not use on live circuits.**

## Ratcheting Cable Cutter

- Cuts hard drawn copper up to 400 KCMIL (MCM) and soft copper, aluminum and multiple conductor cable up to 600 KCMIL (MCM)
- Hardened steel blades ensure consistent cuts and long-term durability
- Rounded blade design minimizes cable distortion during cutting
- Quick release mechanism simplifies blade back-out
- Locking mechanism keeps handles closed for easy storage



Description	Cat. No.
400 KCMIL (MCM) Ratcheting Cable Cutter*	<b>35-056</b>
Replacement blade (moveable side only)	<b>35-085</b>

\*Max. Jaw Opening - 1.375 in. Not for cutting steel or ASCR.

## Ratcheting Cable Cutter

- 750 KCMIL Ratcheting Cable Cutter is designed to cut 750 KCMIL (MCM) and smaller hard-drawn copper and aluminum cables
- Hardened steel blades ensure consistent cuts and long-term durability
- Rounded blade design minimizes cable distortion during cutting
- Quick release mechanism simplifies blade back-out
- Locking mechanism keeps handles closed for easy storage
- Molded-in foot provides stability and leverage when making multiple cuts



Description	Cat. No.
750 KCMIL (MCM) Ratcheting Cable Cutter*	<b>35-053</b>
Replacement blade (moveable side only)	<b>35-057</b>

\*Max. Jaw Opening - 2 in. Not for cutting steel or ASCR.

## Telco Ratcheting Cable Cutters

- Telco Ratcheting Cable Cutter jaw cuts up to 2,700 pair telephone cable and Stalpath® type communications cable
- Hardened steel blades ensure consistent cuts and long-term durability
- Rounded blade design minimizes cable distortion during cutting
- Quick release mechanism simplifies blade back-out
- Locking mechanism keeps handles closed for easy storage
- Molded-in foot provides stability and leverage when making multiple cuts



Description	Cat. No.
Telco Ratcheting Cable Cutter*	<b>35-055</b>
Replacement blade (moveable side only)	<b>35-054</b>

\*Max. Jaw Opening - 3 in. Not for cutting steel or ASCR.

1-800-435-0705 for Customer Service