


## Mounting Pads

- Patented stay-in-place tab keeps cable ties from sliding down during vertical applications
- Lead-N-feature allows easy insertion for hard to reach applications
- Four-sided entry slots save time during placement orientation
- Smooth radius cradle eliminates possible damage to cable while providing stable support
- Webbed punch through screw hole allows maximum adhesive surface area, along with easy insertion of mechanical fasteners
- Low Profile is essential in confined spaces
- UL recognized, rubber adhesive positioning device

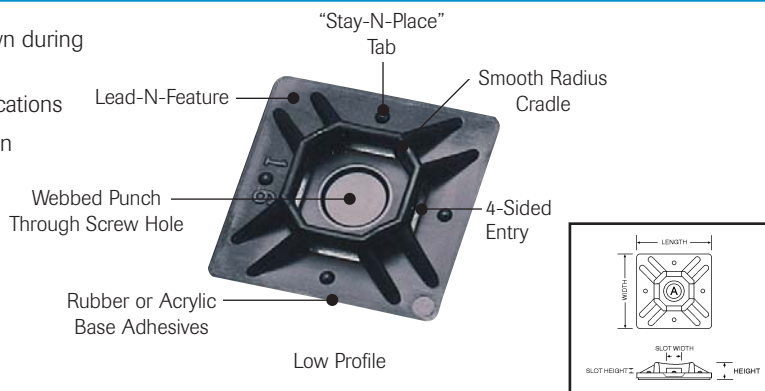

Description	Width	Height	Slot Height	Slot Width	Screw Size	Qty./Bag	Cat. No.
Natural Nylon	.74 in./19mm	.19 in./4.8mm	.05 in./1.2mm	.20 in./5.1mm	No. 4	100	<b>IT750MP-C</b>
UV Black Nylon						100	<b>IT750MP-C0</b>
Natural Nylon	.99 in./25mm	.20 in./5.0mm	.06 in./1.5mm	.20 in./5.1mm	No. 6	100	<b>IT1000MP-C</b>
UV Black Nylon						100	<b>IT1000MP-C0</b>



## Clamps

- Use to secure wires, cables, pipes, tubing, fiber optics
- Ultraviolet black nylon clamps available for internal and external use
- Use with #10 mounting screw



Description	Closed Diameter	Center to Center	Width	Thickness	Mounting Hole	Qty./Bag	Cat. No.
Natural Nylon	.125 in./3.18mm	.343 in./8.71mm	3/8 in.	.050 in./1.27mm	.203 in./5.16mm	100	<b>IT125CCL-C</b>
Natural Nylon	.250 in./6.35mm	.421 in./10.69mm	3/8 in.	.050 in./1.27mm	.203 in./5.16mm	100	<b>IT250CCL-C</b>
UV Black Nylon						100	<b>IT250CCL-C0</b>
Natural Nylon	.375 in./9.52mm	.500 in./12.70mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT375CCL2-C</b>
UV Black Nylon						100	<b>IT375CCL2-C0</b>
Natural Nylon	.500 in./12.70mm	.553 in./14.05mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT500CCL2-C</b>
Natural Nylon	.625 in./15.88mm	.625 in./15.88mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT625CCL2-C</b>
Natural Nylon	.750 in./19.05mm	.699 in./17.75mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT750CCL2-C</b>
Natural Nylon	1.000 in./25.40mm	.825 in./20.96mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT1000CCL2-C</b>

## Flexible Tubing\*

- Flexible polyethylene cuts easily to desired length
- Splits open for neat "bundling" of wiring jobs
- Snaps shut to create a continuous protective cover

Description	Qty.	Cat. No.
3/8 in. Flexible Tubing	10 ft.	<b>772240</b>
3/8 in. Flexible Tubing	1,200 ft.	<b>772245</b>
1/2 in. Flexible Tubing	1 ft.	<b>772241</b>
1/2 in. Flexible Tubing	900 ft.	<b>772244</b>
1 in. Flexible Tubing	5 ft.	<b>772242</b>
1 in. Flexible Tubing	250 ft.	<b>772243</b>

\*Buchanan branded

