


# WeatherProof™ and UnderGround™ Wire Connectors

- Silicone-based sealant protects against moisture and corrosion
- UL Listed to 486D for use in damp/wet locations or direct burial
- Easy to apply, pre-filled twist-on wire connectors
- Handles wire sizes from 22 to 6 AWG copper conductors
- Tough, UL 94V-2 flame-retardant shell rated at 105°C (221°F)
- UL Listed to 486C and CSA Certified to C22.2 #188; comply with Federal Specification W-S-610E

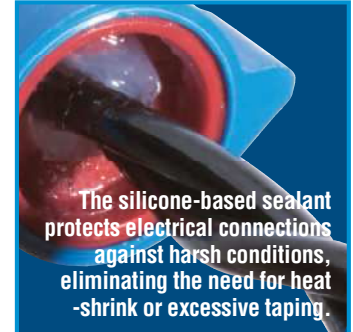




**WeatherProof™** – suitable for interior and exterior electrical connections exposed to rain or damp conditions.




**UnderGround™** – suitable for use in a wide variety of direct burial and wet location electrical connections.



## WeatherProof™ Wire Connectors

Model	Color	Wire Combination Range	Wire Combination Range (mm)	Quantity	Cat. No.
61 	Blue/Orange	600V* 22 to 14 AWG Min. 2 #20 Max. 2 #14	600V* ,34mm <sup>2</sup> to 4,0mm <sup>2</sup> Min. 2-.5mm <sup>2</sup> Max. 2-2,5mm <sup>2</sup>	Card of 6	<b>30-061</b>
				Card of 25	<b>30-161</b>
				Box of 100	<b>30-261</b>
				Box of 1,000	<b>30-361</b>
62 	Blue/Red	600V* 18 to 8 AWG Min. 2 #18 Max. 3 #10	600V* ,75mm <sup>2</sup> to 10,0mm <sup>2</sup> Min. 2-.75mm <sup>2</sup> Max. 3-6,0mm <sup>2</sup>	Card of 5	<b>30-062</b>
				Card of 20	<b>30-162</b>
				Box of 100	<b>30-262</b>
				Box of 1,000	<b>30-362</b>
63 	Blue/Dk. Blue	600V* 16 to 6 AWG Min. 3 #14 Max. 5 #10	600V* 1,5mm <sup>2</sup> to 16,0mm <sup>2</sup> Min. 2-2,5mm <sup>2</sup> Max. 2-10,0mm <sup>2</sup> w/1-6,0mm <sup>2</sup>	Card of 3	<b>30-063</b>
				Card of 15	<b>30-163</b>
				Box of 100	<b>30-263</b>
				Box of 1,000	<b>30-363</b>

## UnderGround™ Wire Connectors

Model	Color	Wire Combination Range	Wire Combination Range (mm)	Quantity	Cat. No.
60 	Blue/Blue	600V* 20 to 10 AWG Min. 1 #20 w/1 #18 Max. 1 #10 w/2 #12	600V* ,5mm <sup>2</sup> to 6,0mm <sup>2</sup> Min. 1-.5mm <sup>2</sup> w/1,75mm <sup>2</sup> Max. 1-6,0mm <sup>2</sup> w/2-4,0mm <sup>2</sup>	Card of 2	<b>30-060</b>
				Card of 10	<b>30-760</b>
				Box of 25	<b>30-160</b>
				Box of 100	<b>30-260</b>
64 	Blue/Dk. Blue	600V* 18 to 8 AWG Min. 2 #18 Sol. Max. 3 #10	600V* ,75mm <sup>2</sup> to 10,0mm <sup>2</sup> Min. 2-.75mm <sup>2</sup> Sol. Max. 3-6,0mm <sup>2</sup>	Box of 1,000	<b>30-360</b>
				Card of 2	<b>30-064</b>
				Card of 10	<b>30-764</b>
				Box of 50	<b>30-264</b>
66 	Blue/Dk. Blue	600V* 14 to 6 AWG Min. 3 #12 Max. 2 #6 w/1 #10	600V* 2,5mm <sup>2</sup> to 16,0mm <sup>2</sup> Min. 3 - 4,0mm <sup>2</sup> Max. 2 - 16,0mm <sup>2</sup> w/1-6,0mm <sup>2</sup>	Box of 1,000	<b>30-364</b>
				Card of 2	<b>30-066</b>
				Card of 6	<b>30-766</b>
				Box of 50	<b>30-266</b>

