


Standard and Heavy-Duty Toggle Switches

- Great for power tool and motor control switch applications
- Rugged long-wearing solid brass/nickel-plated bushings
- 1/2 in. diameter mounting hole
- Dielectric Strength: 1500V
- Mechanical Life: 100,000 cycles
- Operating Temperature: 32°F to 185°F (0°C to 85°C)
- DC Rating: Factory tested 100,000 cycles to 21 Amp 14.8 VDC
- Bulk packaging of 100 available upon request

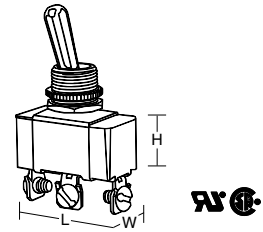

Toggle Switches

Product	Description	Poles	Circuitry	Termination Style	No. of Terminals	Rating			Dimensions (L" x W" x H")	Cat. No.
						Amps 125 VAC	Amps 277 VAC	HP 125-250 VAC		
	Toggle Switch with On-Off Faceplate	SPST	On-Off	Screw	2	20	10	3/4	1.13 x .57 x .61	774011
				Spade						774011BK†
	Toggle Switch		On-Off	"O" Ring & Screw						774008
			(On)-Off	Screw						774008BK†
			On-(Off)	Screw						774010
				Screw						774093
				Screw						774088
774088BK†										
	Toggle Switch w/boot	SPST	On-Off	Wire leads w/boot	2	20	20	1-1/2	1.18 x .68 x .75	774111
										774111BK†
	Toggle Switch	SPDT	On-On	Screw	3	20	10	3/4	1.13 x .57 x .61	774012
	Toggle Switch	SPDT	On-On	Spade	3	20	10	3/4	1.13 x .57 x .61	774100
	Toggle Switch	SPDT	On-Off-On	Screw	3	20	10	3/4	1.13 x .57 x .61	774013
	Toggle Switch	SPDT	On-Off-On	Spade	3	20	10	3/4	1.13 x .57 x .61	774013BK†
	Toggle Switch	SPDT	On-Off-(On)	Screw	3	20	10	3/4	1.13 x .57 x .61	774027
	Toggle Switch	SPDT	(On)-Off-(On)	Screw	3	20	10	3/4	1.13 x .57 x .61	774094
	Heavy-Duty Toggle Switch	DPST	On-Off	Screw	4	20	10	1-1/2	1.30 x .76 x .80	774009
	Heavy-Duty Toggle Switch	DPST	On-Off	Spade	4	20	10	1-1/2	1.30 x .76 x .80	774014
	Heavy-Duty Toggle Switch	DPST	(On)-Off	Screw	4	20	10	1-1/2	1.30 x .76 x .80	774014BK†
	Heavy-Duty Toggle Switch	DPST	On-(Off)	Screw	4	20	10	1-1/2	1.30 x .76 x .80	774005
	Heavy-Duty Toggle Switch	DPST	On-(Off)	Screw	4	20	10	1-1/2	1.30 x .76 x .80	774005BK†
										774103
										774105

() denotes momentary action

†Bulk Package of 100

