



Lever and Pull Chain Switches

- Use for ceiling fixtures, lamps and fans
- Wire leads are #18 AWG, 6 in. stripped wire
- Push in connectors for #18 AWG wire
- 13/32 in. diameter mounting hole
- Bulk packaging of 100 available upon request

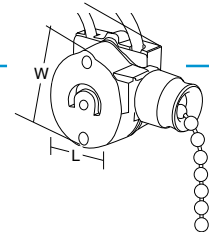


Product	Description	Pull-Chain Color	Poles	Circuitry	Termination Type	Circuit	Rating			Dimensions (L" x W" x H")	Cat. No.
							Amps 125 VAC	Amps 250 VAC	Amps 125 VL		
	All-Angle Lever Switch*	Nickel	SPST	On-Off	Wire Leads	2 Pos - 2 Wire	6	3	—	1.50 x 1.28 x .50	774035
	Pull Chain	Nickel	SPST	On-Off	Wire Leads	2 Pos - 2 Wire	6	3	3	.92 x .88 x .67	774031
	Pull Chain	Brass	SPST	On-Off	Wire Leads	2 Pos - 2 Wire	6	3	3	.92 x .88 x .67	774032
	2-Speed Pull Chain*	Brass	SPDT	Off-On-On	Push-In	3 Pos - 3 Wire	6	3	6	1.43 x 1.25 x .73	774033
	3-Speed Pull Chain*	Brass	SPTT	Off-On-On-On	Push-In	4 Pos - 4 Wire	6	3	—	1.43 x 1.25 x .73	774034
	3-Speed Pull Chain	Brass	SPTT	Off-On(A)-On(B)-On(A+B)	Wire Leads	4 Pos - 3 Wire	6	3	—	.87 x 1.05 x .65	774037
											774037BK†

 Chain/Cord Switches



Cord Switches

- Place your lighting controls in a convenient location with a lamp cord toggle switch
- Available in brown or ivory
- Bulk packaging available upon request

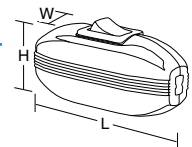

Product	Description	Color	Poles	Circuitry	Termination Style	Ratings	Dimensions (L" x W" x H")	Cat. No.
	Cord Switch	Ivory	SPST	On-Off	Pass Thru	6 Amp 125VAC, 3 Amp 250VAC, 3 Amp 125VT	1.38 x .62 x .73	774072 774072BK†
	Cord Switch	Brown	SPST	On-Off	Pass Thru	6 Amp 125VAC, 3 Amp 250VAC, 3 Amp 125VT	1.38 x .62 x .73	774071 774071BK†
	Cord Toggle Switch	Ivory	SPST	On-Off	Pass Thru	10 Amp 125VAC, 5 Amp 250VAC	2.50 x .83 x 1.28	774074 774074BK†
	Cord Toggle Switch	Brown	SPST	On-Off	Pass Thru	10 Amp 125VAC, 6 Amp 250VAC	2.50 x .83 x 1.28	774073

†Bulk Package of 100

