


Full-Size Rocker Switches

- For commercial appliances, industrial controls, automotive and marine applications
- Moisture- and dust-resistant
- Suitable for low-voltage DC applications
- Recommended .830 in. x 1.450 in. mounting hole, .125 in. panel thickness
- Operating temperature: 32°F to 185°F (0°C to 85°C)
- Bulk packaging available upon request

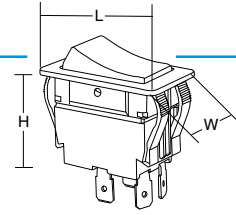

Product	Description	Poles	Circuitry	Termination Style	No. of Terminals	Rating			Dimensions (L" x W" x H")	Cat. No.
						Amps 125 VAC	Amps 277 VAC	HP 110-250 VAC		
	Black Rocker Switch	SPST	On-Off	Spade	2	20	15	2	1.70 x .97 x 1.09	774045
										774045BK†
	Black Rocker Switch	DPST	(On)-Off	Spade	4	20	15	2	1.70 x .97 x 1.09	774120
	Black Rocker Switch	DPST	On-(Off)	Spade	4	20	15	2	1.70 x .97 x 1.09	774121
	Black Rocker Switch	DPDT	On-On	Spade	6	20	15	2	1.70 x .97 x 1.09	774050
	Black Rocker Switch	DPDT	(On)-On	Spade	6	20	15	2	1.70 x .97 x 1.09	774122
	Black Rocker Switch	DPDT	On-Off-On	Spade	6	20	15	2	1.70 x .97 x 1.09	774040
										774040BK†
	Black Rocker Switch	DPDT	(On)-Off-On	Spade	6	20	15	2	1.70 x .97 x 1.09	774123
	Black Rocker Switch***	DPDT	(On)-Off-(On)	Spade	6	15	10*	3/4**	1.70 x .97 x 1.09	774054
										774054BK†
	Red Lighted Rocker*** Switch	DPST	On-Off	Spade	4	15	10*	3/4**	1.70 x .97 x 1.09	774056
	Amber Lighted Rocker*** Switch	DPST	On-Off	Spade	4	15	10*	3/4**	1.70 x .97 x 1.09	774055

() Denotes momentary action *Amps 250 VAC **HP 125-250VAC †Bulk package of 100

