



TOOLS & SUPPLIES


INDICATOR LIGHTS


Indicator Light Part No. System

| Series | Voltage | Color | Mounting Diameter Lens Style | Terminators |
|--------|----------|-----------|---------------------------------|----------------------|
| 77 | 5 - 14V | 1 - Red | 1 - 1/2 in. Raised | 1 - 6 in. Wire Leads |
| | 6 - 28V | 2 - Green | 2 - 1/2 in. Flush | 2 - .187 in. Spade |
| | 7 - 125V | 3 - Amber | 3 - 5/16 in. Flush | — |
| | 8 - 250V | 4 - Blue | — | — |
| | — | 5 - Clear | — | — |

Flush Indicator Lights

- Nylon body with flush transparent polycarbonate lens and stainless steel bezel, 94V-2 flammability rating
- 6 in. wire leads, 1/2 in. mounting diameter
- Lamp voltage is AC/DC
- Operating Temperature: Nylon Body: 140°C
Polycarbonate lens: 135°C

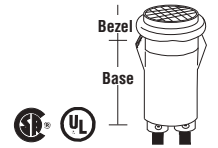


| Product | Description | Lens Color | Lamp Voltage | Watts | Amp Rating | Average Life (hrs.) | Lamp Type | Termination Style | Height (Base" x Bezel") | Cat. No. |
|--|-----------------------|------------|--------------|-------|------------|---------------------|-----------|-------------------|-------------------------|-----------|
|  | Flush Indicator Light | Red | 125V | 1/3 | 2mA Max. | 25,000 | Neon | 6" Wire Leads | .91 x .10 | 777121* |
| | | | | | | | | | | 777121BK† |
| | Flush Indicator Light | Green | 125V | 1/3 | 2mA Max. | 15,000 | Neon | 6" Wire Leads | .91 x .10 | 777221 |
| | | | | | | | | | | 777221BK† |
| | Flush Indicator Light | Amber | 125V | 1/3 | 2mA Max. | 25,000 | Neon | 6" Wire Leads | .91 x .10 | 777321 |
| | | | | | | | | | | 777321BK† |



*VDE certified

†Bulk Package of 100

Raised Indicator Lights

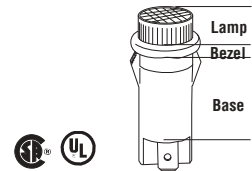- Nylon body with raised transparent polycarbonate lens and stainless steel bezel, 94V-2 flammability rating
- 1/2 in. mounting diameter
- Lamp voltage is AC/DC
- Operating Temperature: Nylon Body: 140°C
Polycarbonate lens: 135°C



| Product | Description | Lens Color | Lamp Voltage | Watts | Amp Rating | Average Life (hrs.) | Lamp Type | Termination Style | Height (Base" x Bezel") | Cat. No. |
|---|------------------------|------------|--------------|-------|------------|---------------------|--------------|-------------------|-------------------------|-----------|
|  | Raised Indicator Light | Red | 14V | 1.2 | .08 | 50,000 | Incandescent | 6" Wire Leads | .91 x .10 x .20 | 775111* |
| | | Red | 28V | 1.2 | .04 | 25,000 | Incandescent | 6" Wire Leads | .91 x .10 x .20 | 776111* |
| | | Green | 28V | 1.2 | .04 | 25,000 | Incandescent | 6" Wire Leads | .91 x .10 x .20 | 776211* |
| | | Amber | 28V | 1.2 | .04 | 25,000 | Incandescent | 6" Wire Leads | .91 x .10 x .20 | 776311* |
| | | Red | 125V | 1/3 | 2mA Max. | 25,000 | Neon | 6" Wire Leads | .91 x .10 x .20 | 777111* |
| | | Green | 125V | 1/3 | 2mA Max. | 15,000 | Neon | 6" Wire Leads | .91 x .10 x .20 | 777211* |
| | | Amber | 125V | 1/3 | 2mA Max. | 25,000 | Neon | 6" Wire Leads | .91 x .10 x .20 | 777311* |
| | | Red | 250V | 1/2 | 2mA Max. | 25,000 | Neon | 6" Wire Leads | .91 x .10 x .20 | 778111* |
| | | Green | 250V | 1/2 | 2mA Max. | 15,000 | Neon | 6" Wire Leads | .91 x .10 x .20 | 778211* |
|  | Raised Indicator Light | Green | 28V | 1.2 | .04 | 25,000 | Incandescent | .187" Spade | 1.09 x .10 x .20 | 776212BK† |
| | | Amber | 28V | 1.2 | .04 | 25,000 | Incandescent | .187" Spade | 1.09 x .10 x .20 | 776312BK† |
| | | Red | 125V | 1/3 | 2mA Max. | 25,000 | Neon | .187" Spade | 1.09 x .10 x .20 | 777112 |
| | | Green | 125V | 1/3 | 2mA Max. | 15,000 | Neon | .187" Spade | 1.09 x .10 x .20 | 777112BK† |
| | | | | | | | | | | 777212BK† |

*VDE certified

†Bulk Package of 100