



# DATA COMM/NETWORKS

## Kinetic Super™ Wire Stripper/Crimper

- Cuts and strips 22 to 24 AWG
- Crimps IDC Connectors




Description	Cat. No.
Kinetic Super™ Wire Stripper/Crimper Kit – includes 25 IDC connectors (UR-I, 3-Wire Butt Splice)	<b>33-719</b>

## Insulation Displacement Connectors

IDC connectors create fast splice and tap connections on solid copper wires. Designed for low voltage telecommunication cables.

- Moisture-resistant sealant protects wires from corrosion
- Use with solid copper single-conductor wire
- Kinetic Super™ Wire Stripper/Crimper easily cuts and strips 22 to 24 AWG solid wire

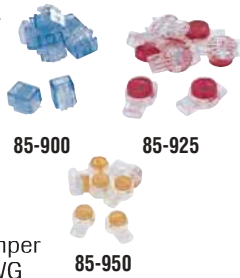

Description	Qty.	Cat. No.
UR-I, 3-Wire Butt Splice IDC	25	<b>85-925</b>
UR-I, 2-Wire Butt Splice IDC	100	<b>86-925</b>
UR-I, 3-Wire Butt Splice IDC	1,000	<b>87-925</b>
IDC Connector Combo Pack – includes 10 UR, 10 UY and 5 UB	25	<b>85-960</b>
UY-I, 2-Wire Butt Splice IDC	25	<b>85-950</b>
UB-I, 2-Wire Tap Splice IDC	25	<b>85-900</b>

## Strain Relief Boots for Modular Plugs

- Prevents broken connector tabs and snagging while extending connector life
- Minimizes cable bends that can reduce data speed and result in data loss
- Dampens cable movement and vibrations that can result in premature connector failure



Description	Qty.	Cat. No.
Strain Relief Boots for Modular Plugs	25	<b>85-380</b>
15 Strain Relief Boots and 15 8P8C RJ-45 Modular Plugs	15	<b>85-379</b>

## Modular Plugs

- Plugs support the latest cable system performance categories when installed in compliance with appropriate standards and methods
- Plugs work with 24 AWG solid or stranded conductors and round or flat cables.

Description	Qty.	Cat. No.
8-Position 8-Contact, RJ-45	10	<b>85-147</b>
	25	<b>85-346</b>
	50	<b>85-396</b>
	100	<b>86-396</b>
6-Position 6-Contact, RJ-11	25	<b>85-345</b>
6-Position 4-Contact, RJ-11	25	<b>85-344</b>

## CAT 6 RJ-45 Modular Plugs

- Three-piece design provides easy installation and optimal performance
- Crimps with a standard RJ-45 crimp die
- 50 micron gold contacts, 8-position, 8-contact
- Suitable for solid or stranded conductors – 23 AWG



Description	Qty.	Cat. No.
CAT 6 RJ-45 Modular Plugs	25	<b>85-366</b>

## Wiring Configurations for Modular Plugs

