
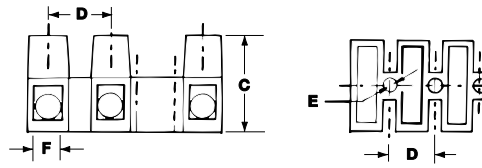


Barrier Strips

- Recessed screws and tubular contacts provide added safety and help prevent short circuits
- Tubular contacts connect stripped, un-terminated solid or stranded wire directly to each contact
- Integrated wire protectors prevent twisting and breakage of stranded wire during connection
- Modular 12-circuit design can be cut into smaller sections, or stacked end-to-end
- Rugged nylon construction, UL 94V2
- Operating temperature rated to 105°C (221°F)

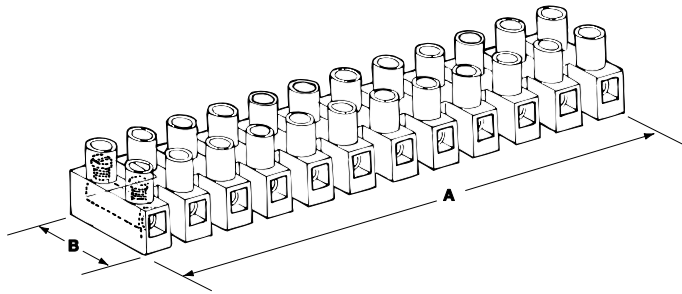

Barrier Strips

| Electrical Ratings | Wire Range (AWG) | No. of Circuits | Torque in.-lb. | Model No. | Dimensions (Inches) | | | | | | Dimensions (mm) | | | | | | Cat. No. |
|--------------------|------------------|-----------------|----------------|-----------|---------------------|-------|-------|-------|-------|-------|-----------------|------|------|------|-----|-----|---------------|
| | | | | | A | B | C | D | E | F* | A | B | C | D | E | F** | |
| 20A/600V UL | 22 - 12 | 12 | 3.5 | PA8DS | 3.787 | 0.669 | 0.570 | 0.315 | 0.114 | 0.110 | 96.2 | 17.0 | 14.5 | 8.0 | 2.9 | 2.8 | 89-608 |
| 10A/400V CSA | 20 - 18 | | | | | | | | | | | | | | | | |
| 30A/600V UL | 22 - 10 | 12 | 4.4 | PA10DS | 4.626 | 0.795 | 0.670 | 0.394 | 0.142 | 0.134 | 117.0 | 20.2 | 17.0 | 10.0 | 3.6 | 3.4 | 89-610 |
| 20A/400V CSA | 18 - 14 | | | | | | | | | | | | | | | | |
| 35A/600V UL/CUL | 22 - 10 | 12 | 7.0 | PA12DS | 5.540 | 0.937 | 0.748 | 0.472 | 0.154 | 0.154 | 140.7 | 23.8 | 19.0 | 12.0 | 3.9 | 3.9 | 89-612 |
| 50A/600V UL/CUL | 20 - 8 | 12 | 12.0 | PA14DS | 6.220 | 1.008 | 0.992 | 0.531 | 0.173 | 0.189 | 158.0 | 25.6 | 25.2 | 13.5 | 4.4 | 4.8 | 89-614 |

*Plus or minus .004 in.

**Plus or minus 0.1mm

