



## Phillips

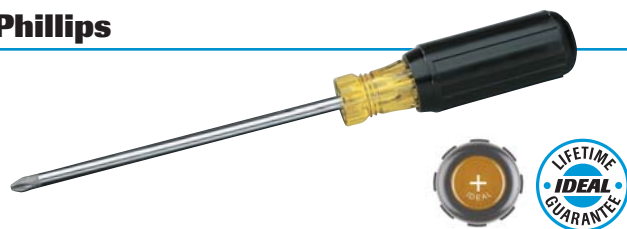

- Vapor-blasted tip prevents plate chipping
- Identification mark on ends
- Nickel-chrome plating for corrosion resistance
- Tough, chrome vanadium steel shank
- Cushioned rubber grip

Description	Blade Length	Total Length	Cat. No.
#1 Tip Phillips	3 in.	6-3/4 in.	<b>35-193</b>
#2 Tip Phillips	1 in.	3-3/8 in.	<b>35-191</b>
#2 Tip Phillips	4 in.	8-3/8 in.	<b>35-194</b>
#2 Tip Phillips	6 in.	10-3/8 in.	<b>35-195</b>
#3 Tip Phillips	6 in.	11 in.	<b>35-196</b>


## Square Head

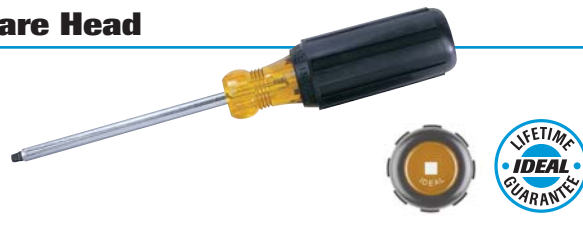

- Precise tip for square-recess screws
- Color-coded handle for easy identification
- Nickel-chrome plating for corrosion resistance
- Tough, chrome vanadium steel shank
- Cushioned rubber grip

Description	Color Code	For Screw Sizes	Cat. No.
#0 x 4 in.	Yellow	3, 4	<b>35-690</b>
#1 x 4 in.	Green	5, 6, 7	<b>35-691</b>
#1 x 8 in.	Green	5, 6, 7	<b>35-692</b>
#2 x 4 in.	Red	8, 9, 10	<b>35-693</b>
#2 x 8 in.	Red	8, 9, 10	<b>35-694</b>
#3 x 4 in.	Black	12, 14	<b>35-695</b>
#3 x 8 in.	Black	12, 14	<b>35-696</b>

## Quick-Rotating

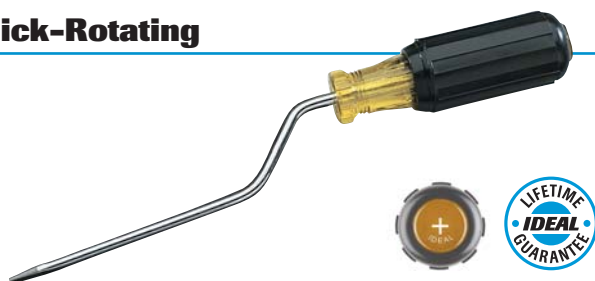

- Ideal for threading screws in switches, fixtures and anchors
- Identification mark on ends
- One-handed crank action for quick and easy use
- Vapor-blasted tip prevents plate chipping
- Precision-ground tip provides secure fit in screw slot
- Nickel-chrome plating for corrosion resistance
- Tough, chrome vanadium steel shank
- Cushioned rubber grip

Description	Total Length	Cat. No.
3/16 in. Shank and Tip	8-3/4 in.	<b>35-200</b>
#2 Phillips Tip and 1/4 in. Shank	9-3/4 in.	<b>35-203</b>


## Awl



- Heavy-duty construction for piercing, punching and scribing
- Identification mark on end
- Cushioned rubber grip

Description	Blade Length	Total Length	Cat. No.
Awl	3 in.	6-3/4 in.	<b>35-202</b>

## Screw-Holding

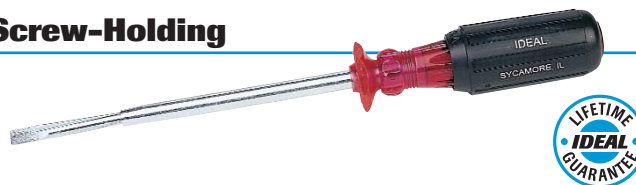

- Split blade wedges into screw slot when collar is extended
- Holds screw in place when installing in hard-to-reach locations
- Tough, chrome vanadium steel shank and comfort grip handle

Description	Blade Length	Total Length	Cat. No.
3/16 in.	4 in.	8 in.	<b>35-404</b>
3/16 in.	6 in.	10 in.	<b>35-406</b>
3/16 in.	8 in.	12 in.	<b>35-408</b>