


Electric Plug Lockout

- Slides over cord prongs and locks in place to prevent cord from being plugged into an outlet
- Cannot be removed without key
- Works on any 2- or 3-prong plug



| Description | Part No. |
|-----------------------|----------|
| Electric Plug Lockout | 44-782 |

Wall Switch Lockouts

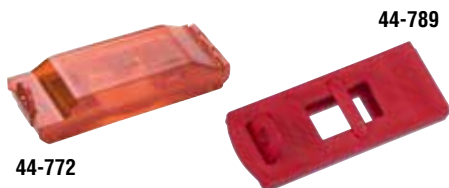


- Universal Wall Switch Lockout locks out both toggle and Decora® wall switches
- Universal design assures switch is locked on or off. Hinges open for unobstructed normal switch operation
- Standard wall switch lockout fits most wall-mounted single or three-way electrical switches

| Description | Quantity | Part No. |
|-----------------------|----------|----------|
| Universal Wall Switch | 1 | 44-772 |
| Standard Wall Switch | 1 | 44-789 |

Decora® is a registered trademark of Leviton Manufacturing Co., Inc.

Adjustable Cable Lockout

- Infinitely adjustable safety hasp and cable
- Ideal for multiple circuit breaker panels and side-by-side gate valve lockouts
- Feed the cable end through the points to be locked out, then back through the lockout body. Cinch it tight to remove any slack with the patented locking feature.
- Tough, flexible multi-stranded 6 ft. 1/4 in. dia. steel cable is insulated with a clear vinyl coating
- Tough, lightweight, dielectric thermoplastic body withstands chemicals; performs effectively in extreme conditions
- Up to four workers can apply their personal safety locks
- Complete with high-visibility, re-usable, write-on safety labels (English, French & Spanish). Identify the responsible person, then erase for the next job.

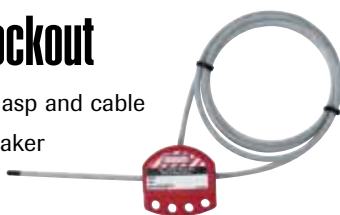

| Description | Part No. |
|--------------------------|----------|
| Adjustable Cable Lockout | 44-808 |

Cable Lockout

- Unique hasp lockout device accepts up to six 9/32 in. padlocks and comes with a 6 ft. plastic-coated steel cable



| Description | Part No. |
|----------------------------|----------|
| Cable Lockout, 6 ft. cable | 44-829 |

Gate Valve Lockouts



- Unique patent pending rotating design allows for easier installation in confined space applications
- Each size rotates into itself and nests within the next larger size to save space in storage
- Up to four workers can apply their personal safety locks
- Complete with high-visibility permanent safety labels (English, French & Spanish) that can be written on to identify the responsible person, then erased for the next job
- Tough, lightweight, dielectric thermoplastic bodies withstand chemicals and perform effectively in extreme conditions, temperature range: -50°F (-46°C) to +350°F (177°C)

| Valve Size | Quantity | Part No. |
|-------------------------------------|----------|----------|
| 1 in. to 3 in. | 1 | 44-824 |
| 2 in. to 5 in. | 1 | 44-825 |
| Set of five sizes (1 in. to 13 in.) | 1 | 44-817 |

Ball Valve Lockout Devices

- Best available method for locking out ball valves
- Patented design fits most major brand ball valves
- Designed to lock in off position only
- Complies with OSHA lockout standard



44-847

| Valve Size | Max. Shackles Length | Material | Part No. |
|------------------------|----------------------|---------------|----------|
| 1/2 to 1-1/4 in. | — | Polypropylene | 44-846 |
| 1-1/4 to 3 | — | Polypropylene | 44-847 |
| 1/4 to 1 (not shown) | 9/32 in. | Nylon | 44-820 |
| 1-1/4 to 3 (not shown) | 9/32 in. | Heavy Steel | 44-821 |