


## Grommets\*

- Installs instantly! Flexible PVC grommets side slotted 1/16" for quick installation
- Snap into holes in electrical boxes, sheet metal, auto firewalls and more
- Prevents steel and other sharp edge chafing of wire insulation or cording
- Black, PVC, flexible, 60 durometer

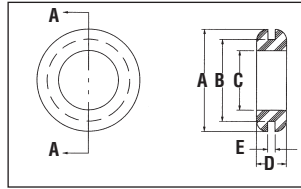

Description	A	B	C	D	E	Quantity	Cat. No.
1/4" Grommets	9/16	.37	1/4	.28	3/32	6	774114
1/4" Grommets	9/16	.37	1/4	.28	3/32	25	774116
1/4" Grommets	9/16	.37	1/4	.28	3/32	1,000	774114BK
3/8" Grommets	43/64	.49	3/8	.28	1/16	5	774138
3/8" Grommets	43/64	.49	3/8	.28	1/16	25	774137
1/2" Grommets	55/64	.69	1/2	.25	1/16	4	774112
1/2" Grommets	55/64	.69	1/2	.25	1/16	25	774113
3/4" Grommets	15/64	1.0	3/4	.31	1/16	3	774134
3/4" Grommets	15/64	1.0	3/4	.31	1/16	25	774136

\*Buchanan branded

## Wire Marker Booklets\*

- Self-sticking on wire and cable
- Perforated 1/4" x 1-1/2" markers
- For applications above or below ground
- Resists abrasion, moisture, dirt and oil
- Non-smear black legend ensures high visibility


 



Legend	Quantity	Cat. No.
0-9	45	775101
A-Z, 0-15, +, -, /	10	775102
1-45	10	775103
46-90	10	775104


\*Buchanan branded

## Universal Metal Stud Bushings

- Non-metallic stud bushing fits all hole configurations you are likely to encounter in pre-punched steel studs
- Long pulls of cable slide smoothly through the bushing, make a difficult job easier
- Protects wire without falling out of the hole

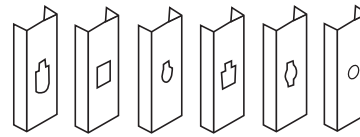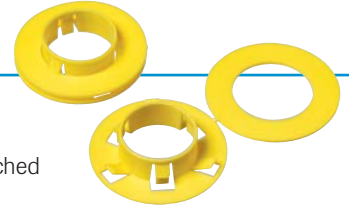

Common hole configurations in metal studs.

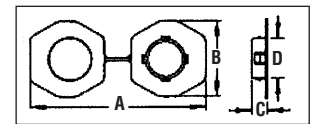

Description	A	B	C	D	Quantity	Cat. No.
Stud Bushing	5.670	2.50	.505	1.30	25	772271