

## Vinyl Insulated Snap Spade Terminals




Wire Range (AWG)	Wire Range (mm <sup>2</sup> )	Stud Size (Inches)	Stud Size (mm)	Max. Wire Ins. Dia. (Inches)	Max. Wire Ins. Dia. (mm)	Dimensions (Inches)				Dimensions (mm)				Ctn. Qty.	Cat. No.
						L	W	E	F	L	W	E	F		
22 - 18	0.5 - 1.0	6	3.7	.134	4.0	.827	.252	.394	.256	21.0	6.4	10.0	6.5	25	83-7011
		8	4.3			.827	.283	.394	.256	21.0	7.2	10.0	6.5		
		10	5.3			.827	.319	.394	.256	21.0	8.1	10.0	6.5		
16 - 14	1.5 - 2.5	6	3.7	.161	4.5	.827	.236	.394	.256	21.0	6.0	10.0	6.5	25	83-7051
		8	4.3			.827	.319	.394	.256	21.0	8.1	10.0	6.5		
		10	5.3			.827	.319	.394	.256	21.0	8.1	10.0	6.5		
12 - 10	4.0 - 6.0	8	4.3	.248	6.3	.992	.327	.512	.276	25.2	8.3	13.0	7.0	25	83-7081
		10	5.3			.992	.354	.512	.276	25.2	9.0	13.0	7.0		
		1/4	6.4			1.240	.472	.512	.472	31.5	12.0	13.0	12.0		

75° C/600 Volts max.

Listed 774A Cu Only Pressure Wire Connector

## Non-Insulated Spade Terminals

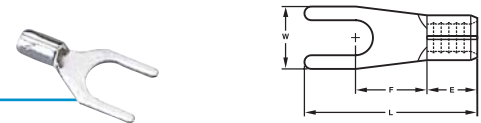

Wire Range (AWG)	Wire Range (mm <sup>2</sup> )	Stud Size (Inches)	Stud Size (mm)	Dimensions (Inches)				Dimensions (mm)				Ctn. Qty.	Cat. No.	Ctn. Qty.	Cat. No.
				L	W	E	F	L	W	E	F				
22 - 18	0.5 - 1.0	6	3.7	.630	.252	.189	.256	16.0	6.4	4.8	6.5	25	83-6111	—	—
		8	4.3	.630	.283	.189	.256	16.0	7.2	4.8	6.5	25	83-6121		
		10	5.3	.630	.319	.189	.256	16.0	8.1	4.8	6.5	25	83-6131		
16 - 14	1.5 - 2.5	8	4.3	.630	.283	.189	.256	16.0	7.2	4.8	6.5	25	83-6161	1,000	84-6171
		10	5.3	.630	.366	.189	.256	16.0	9.3	4.8	6.5	25	83-6171		
12 - 10	4.0 - 6.0	8	4.3	.728	.354	.236	.276	18.5	9.0	6.0	7.0	25	83-6211	—	—
		10	5.3	.728	.354	.236	.276	18.5	9.0	6.0	7.0	25	83-6221		
		1/4	6.4	.965	.472	.236	.472	24.5	12.0	6.0	12.0	25	83-6231		

105° C/600 Volts max.

Listed 774A Cu Only Pressure Wire Connector

## Vinyl Insulated Multi-Stack Disconnects



Wire Range (AWG)	Wire Range (mm <sup>2</sup> )	Tab Size (Inches)	Tab Size (mm)	Max. Wire Ins. Dia. (Inches)	Max. Wire Ins. Dia. (mm)	Dimensions (Inches)						Dimensions (mm)						Ctn. Qty.	Cat. No.
						L	B	W	F	W1	F1	L	B	W	F	W1	F1		
22 - 18	0.5 - 1.0	.250 x .032	6.35 x 0.8	.150	3.8	.886	.413	.260	.315	.250	.323	22.5	10.5	6.6	8.0	6.35	8.2	25	83-9611
16 - 14	1.5 - 2.5	.250 x .032	6.35 x 0.8	.185	4.7	.886	.413	.260	.315	.250	.323	22.5	10.5	6.6	8.0	6.35	8.2	25	83-9621
12 - 10	4.0 - 6.0	.250 x .032	6.35 x 0.8	.244	6.2	.945	.512	.260	.315	.250	.323	22.5	13.0	6.6	8.0	6.35	8.2	25	83-9631

75° C/300 Volts max.

Listed 774A Cu Only Pressure Wire Connector