


Vinyl Insulated Butt Splices

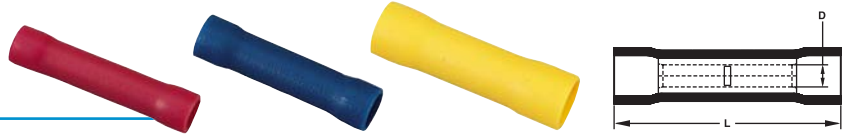

Wire Range (AWG)	Wire Range (mm ²)	Max. Wire Ins. Dia. (Inches)	Max. Wire Ins. Dia. (Inches)	Dimensions (Inches)		Dimensions (mm)		Ctn. Qty.	Cat. No.	Ctn. Qty.	Cat. No.
				L	D	L	D				
22 – 18	0.5 – 1.25	.157	4.0	.986	.067	24.6	1.7	25	83-9281	1,000	84-9281
16 – 14	1.5 – 2.5	.177	4.5	.986	.091	24.6	2.3	25	83-9291	1,000	84-9291
12 – 10	4.0 – 6.0	.248	6.3	1.043	.134	26.5	3.4	25	83-9301	500	84-9301

75° C/600 Volts max.

Listed 774A Cu Only Pressure Wire Connector

Vinyl Insulated Parallel Splices



Wire Range (AWG)	Wire Range (mm ²)	Max. Wire Ins. Dia. (Inches)	Max. Wire Ins. Dia. (mm)	Dimensions (Inches)		Dimensions (mm)		Ctn. Qty.	Cat. No.
				L	W	L	W		
22 – 18	0.5 – 1.0	.157	4.0	.512	.067	13.0	1.7	25	83-9351
16 – 14	1.5 – 2.5	.177	4.5	.512	.091	13.0	2.3	25	83-9361
12 – 10	4.0 – 6.0	.248	6.3	.591	.134	15.0	3.4	25	83-9371

75° C/600 Volts max.

Tap Splice Connectors



Wire Range (AWG)	Wire Range (mm ²)	Color	Dimensions (Inches)		Dimensions (mm)		Ctn. Qty.	Cat. No.
			L	W	L	W		
22 – 18	0.5 – 1.0	Red	1.063	.787	27.0	20.0	25	83-3261
16 – 14	1.5 – 2.5	Blue	1.063	.787	27.0	20.0	25	83-3271
12 – 10	4.0 – 6.0	Yellow	1.358	.807	34.5	20.5	25	83-3281

105° C/600 Volts max.