

Coax Strip and Crimp Tool

- Precision, form-ground stripping holes remove outer jacket and insulation from RG-59 and RG-6 coaxial cable
- Durable blades cut copper-coated steel conductors
- Three crimping nests for crimping F-connectors and ring terminals
- Cushioned, comfort-grip handles



Description	Cat. No.
Coax Strip & Crimp Tool	30-433
Coax Strip & Crimp Tool Kit w/ten RG-6 F-Connectors	30-433F

Round Cable Slitting and Ringing Tool


- Cuts around cable jacket as well as slits the length of jacket for easy removal
- Use with single or multiple conductor cable up to 1.75 in. O.D.
- Blade adjusts for jacket thicknesses up to .125 in.
- Spare blade in handle base



Description	Cat. No.
Round Cable Slitting and Ringing Tool	45-144
Replacement Blades for 45-144 (2/pkg.)	LB-1748

Crimpmaster™ Crimp Tools & Die Sets

Dies change quickly and easily with a screwdriver. Interchangeable dies provide versatility in a single tool

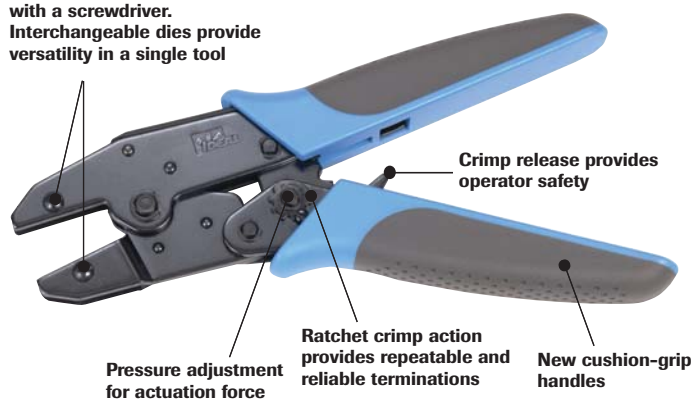

High quality ratchet-type crimp tool for electricians, contractors and installers who require guaranteed repeatability of good mechanical and electrical connections.

Paired Conductor Termination

Description	Tool Cat. No.	Replacement Die Set Cat. No.
Crimpmaster™ Crimp Tool Frame	30-506	—
RJ-45 Eight-position Crimp Tool for AMP RJ-45 modular plugs	30-521	30-560
RJ-45 Eight-position Crimp Tool for keyed or non-keyed modular plugs	30-522	30-559
RJ-11 Crimp Tool for two, four or six-position modular plugs	—	30-556
RJ-11 Crimp Tool for DEC MMJ six-position modular plugs with an off-set release tab	30-525	30-558
Crimpmaster™ Handset Die for four-position handset modular plugs	30-526	30-565

Coaxial Termination

Description	Tool Cat. No.	Replacement Die Set Cat. No.
22-10 AWG (.324mm ² - 5.261mm ²) fully insulated slide-on connectors	—	30-594
Large gauge sound cable	30-478	—
Insulated Terminal Crimp Tool with built-in locator	30-479	—
22-12 AWG (.324mm ² - 3.31mm ²) Non-insulated open barrel crimp style connectors	—	30-586
RG-58, 59, 62 Non-plenum Cambridge BNC/TNC connectors	30-481	30-573
RG-8/11, RG-213, RG-216 Ethernet Thickwire, N-Series type plugs and jacks	30-482	30-577
RG-9, Belden® 8281® and RG-6 Cable, 50 & 75 Ohm	30-483	30-578
RG-58 and RG-174 cable for 50 and 75 Ohm cables	—	30-587
RG-174 Mini-59 Hex BNC/TNC coax connector	30-485	30-576
RG-58 and RG-59 Plenum cables, Thinwire PVC Hex	—	30-591
16-26 AWG (1.31mm ² - 1.28mm ²) Miniature insulated rings and splices	—	30-572
SMA or SFR-Type fiber optic connectors	30-490	30-597
22-10 AWG (.324mm ² - 5.261mm ²) Insulated ring tongue terminals and splices	30-500	30-579
22-8 AWG (.3mm ² - 8mm ²) Non-insulated terminals and splices	—	30-580
RG-58 RG-59/62AU BNC/TNC 3-Piece Hex type connectors	30-502	30-581
CATV RG-59 and RG-6 Captive Ring F-connectors	30-503	30-582
SMA or SFR-Type Hex fiber optic connectors	30-489	30-596