


## TYPE IKS

### Features

- Manufactured from high strength copper alloy
- Electro-tin plated
- Two bolt design
- Longer peened bolt
- Serrated spacer bar
- For copper conductor only

### Benefits

- Allows maximum conductivity and high breakage resistance
- Provides low contact resistance
- Allows maximum pressure to be applied directly to the conductor strands
- Permits a swivel action for easier installation
- Makes a secure connection

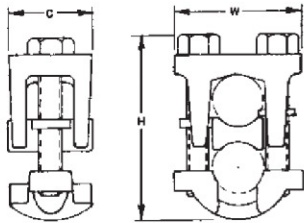

B

Catalog Number	Wire Range		Dimensions		
	Main	Tap	C	H	W
IKS-4/0	4/0-1/0	4/0-6	1.12	2.31	1.72
IKS-350	350kcmil-250kcmil	350kcmil-6	1.38	2.62	2.12
IKS-500	500kcmil-400kcmil	500kcmil-4	1.50	3.00	2.26
IKS-800	800kcmil-400kcmil	800kcmil-4/0	1.62	3.50	2.50
IKS-1000	1000kcmil-500kcmil	1000kcmil-4/0	2.00	4.03	3.03

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)