

# ILSCO Cast Bronze Ground Clamps




## TYPE BGDB

### Features

- Manufactured from bronze alloy
- UL Listed for direct burial in earth or concrete
- Lay-In feature

### Benefits

- Ensures maximum strength and superior conductivity
- Ensures reliability
- Reduces installation time

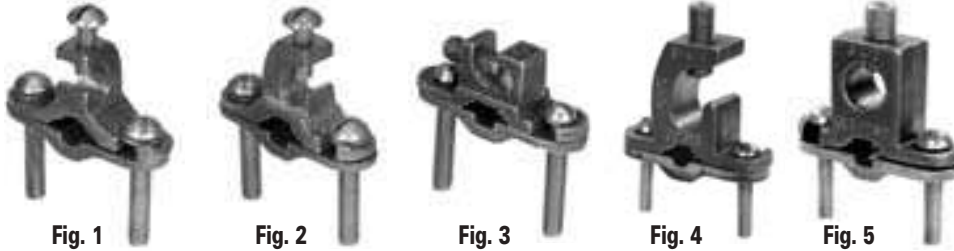

Catalog Number	Figure Number	Pipe Size	Rebar Size	Ground Rod Size	Ground Wire Range	Screw Material	Dimensions	
							L	W
BGC-2T-DB*	1	1/2-1	3/8-1	1/2-1	2str-10sol	silicon bronze	2-3/4	2-1/4
BGC-2P-DB*	2	1/2-1	3/8-1	1/2-1	2str-10sol	silicon bronze	2-3/4	2-1/4
BGC-2PS-DB+	3	1/2-1	3/8-1	1/4-1	2str-10sol 2 #8sol	stainless steel	2-1/4	2-1/4
BGC-4/0P-DB=	4	1/2-1	3/8-1	1/2-1	4/0-8str	stainless steel	3	2-1/4
BGC-4/0S-DB=	5	1/2-1	3/8-1	1/2-1	4/0-8str	stainless steel	2-3/4	2-1/4

\* UL File E207816

+ UL File E198108

= UL File E178441

G



4730 Madison Road, Cincinnati, Ohio 45227-1426 Phone 513 533-6200 Fax 513 871-4084 Web site www.ilsco.com  
**Canada** 1050 Lakeshore Road East, Mississauga, Ontario, Canada L5E1E4 Phone 905 274-2341 Fax 905 274-8763