



# Ground Rod Clamps



## TYPE GRC


### Features

- Manufactured from seamless bronze tubing
- Supplied with silicon bronze "everdur" screw
- UL Listed and CSA Certified for 600 volts except GRC-38 and GRC-75

### Benefits

- Provides maximum strength and superior conductivity
- Ground rod clamp is suitable for direct burial
- Ensures reliability for copper conductor

C

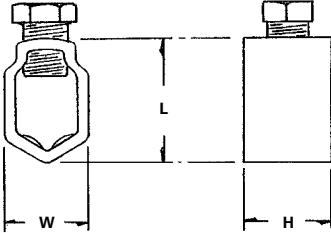

Catalog Number	Ground Rod Size	Ground Wire Range	Rebar Size	Rebar Wire Range	Dimensions	
					L	W
GRC-38	3/8	4-10	-	-	5/8	5/8
GRC-48	1/2	2-10	#4	2-8	7/8	3/4
GRC-58+	5/8 or 3/4	2-8	-	-	15/16	7/8
GRC-68	3/4, 5/8	2-8 for 3/4 rod, 1/0-8 for 5/8 rod	#5	1/0-8	1	1
GRC-75	3/4	3/0-8	-	-	3/4	1-5/32

Plain copper finish. Suitable for burial in earth or concrete.  
+REA Listed.