

TYPE  
**ILC-10-N**

**Features**


- Rotatable die
- Additional die affixed to frame
- Crimp cavities are color coded to industry standards
- Ratchet control mechanism
- Heat treated frame and dies
- Long, molded handles

**Benefits**

- Crimps #2, #4, #6 and #8 copper compression connectors
- Crimps 1/0 and #1 copper compression connectors
- Reduces the possibility of improper die selection
- Assures a complete crimp
- Dependable, long lasting tool
- Ergonomic design to reduce hand stress

**Specifications**

Weight: 1-3/8 lbs.  
 Overall Length: 11"  
 Width: 3.75"  
 Jaw Opening: .5"  
 Conductor Range: 1/0-8 CU

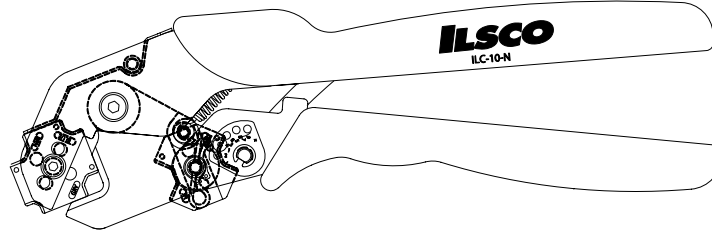

**For Use with**

**Copper Connectors**

CRA, CRB, CRC 1/0-8

CRA-L, CRB-L, CRC-L 1/0-6

CRA-L2, CRB-L2, CRC-L2 1/0-6

BT, BT-45, BT-90 1/0-6

CCL 1/0-8

CCS 1/0-8

CT 1/0-8

CTL 1/0-6

