

TYPE


PBTM

Features

- Mountable
- Broad wire range: 750kcmil-6
- UL Listed for 600 volts, 90° C
- Dual rated
- Cold temperature rated to -45° C
- High dielectric strength plastisol
- Black cover
- Removable plugs
- Prefilled with De-ox®

Benefits

- Isolated mounting in trough, wire way or panels
- Flexibility in the field
- Ensures reliability
- For copper or aluminum conductor
- Application variability
- Chemical resistant
- UV Rated
- Entry port closure
- Prevents oxides from forming

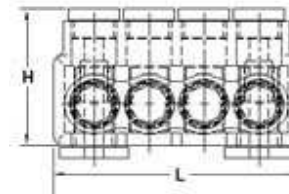

D

Catalog Number	No. Of Ports	Wire Range	Dimensions			Hex Size	Mounting Holes
			L	W	H		
PBTD-2-500-M	2	500kcmil-4	5.28	2.63	3.04	3/8	5/16
PBTD-3-500-M	3	500kcmil-4	6.44	2.63	3.04	3/8	5/16
PBTD-4-500-M	4	500kcmil-4	7.59	2.63	3.04	3/8	5/16
PBTD-5-500-M	5	500kcmil-4	8.75	2.63	3.04	3/8	5/16
PBTD-6-500-M	6	500kcmil-4	9.90	2.63	3.04	3/8	5/16
PBTD-7-500-M	7	500kcmil-4	11.06	2.63	3.04	3/8	5/16
PBTD-8-500-M	8	500kcmil-4	12.22	2.63	3.04	3/8	5/16
PBTD-9-500-M	9	500kcmil-4	13.37	2.63	3.04	3/8	5/16
PBTD-10-500-M	10	500kcmil-4	14.53	2.63	3.04	3/8	5/16
PBTD-11-500-M	11	500kcmil-4	15.68	2.63	3.04	3/8	5/16
PBTD-12-500-M	12	500kcmil-4	16.84	2.63	3.04	3/8	5/16
PBTD-2-750-M*	2	750kcmil-250kcmil	6.32	3.25	3.31	1/2	3/8
PBTD-3-750-M*	3	750kcmil-250kcmil	7.74	3.25	3.31	1/2	3/8
PBTD-4-750-M*	4	750kcmil-250kcmil	9.16	3.25	3.31	1/2	3/8
PBTD-5-750-M*	5	750kcmil-250kcmil	10.58	3.25	3.31	1/2	3/8
PBTD-6-750-M*	6	750kcmil-250kcmil	12.00	3.25	3.31	1/2	3/8
PBTD-7-750-M*	7	750kcmil-250kcmil	13.43	3.25	3.31	1/2	3/8
PBTD-8-750-M*	8	750kcmil-250kcmil	14.85	3.25	3.31	1/2	3/8
PBTD-9-750-M*	9	750kcmil-250kcmil	16.27	3.25	3.31	1/2	3/8
PBTD-10-750-M*	10	750kcmil-250kcmil	17.69	3.25	3.31	1/2	3/8
PBTD-11-750-M*	11	750kcmil-250kcmil	19.11	3.25	3.31	1/2	3/8
PBTD-12-750-M*	12	750kcmil-250kcmil	20.54	3.25	3.31	1/2	3/8

Replacement caps & plugs available. Consult Factory.

* Not UL Listed

Tested to UL 486A-486B, UL File E6207