


**TYPE  
PBTS**
**Features**

- Broad wire range: 750kcmil-14
- UL Listed for 600 volts, 90° C
- Dual rated
- Cold temperature rated to -45° C
- High dielectric strength plastisol
- Black cover
- Removable plugs
- Prefilled with De-ox®

**Benefits**

- Flexibility in the field
- Ensures reliability
- For copper or aluminum conductor
- Application variability
- Chemical resistant
- UV Rated
- Entry port closure
- Prevents oxides from forming

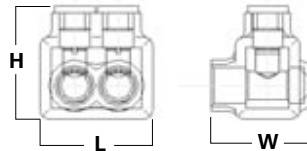

| Catalog Number | No. Of Ports | Wire Range | Dimensions |      |      | Hex Size |
|----------------|--------------|------------|------------|------|------|----------|
|                |              |            | L          | W    | H    |          |
| PBTS-10-3/0    | 10           | 3/0-6      | 8.00       | 1.58 | 1.86 | 3/16     |
| PBTS-11-3/0    | 11           | 3/0-6      | 8.77       | 1.58 | 1.86 | 3/16     |
| PBTS-12-3/0    | 12           | 3/0-6      | 9.54       | 1.58 | 1.86 | 3/16     |
| PBTS-13-3/0    | 13           | 3/0-6      | 10.30      | 1.58 | 1.86 | 3/16     |
| PBTS-14-3/0    | 14           | 3/0-6      | 11.07      | 1.58 | 1.86 | 3/16     |
| PBTS-2-250     | 2            | 250kcmil-6 | 2.17       | 1.91 | 2.17 | 5/16     |
| PBTS-3-250     | 3            | 250kcmil-6 | 3.07       | 1.91 | 2.17 | 5/16     |
| PBTS-4-250     | 4            | 250kcmil-6 | 3.96       | 1.91 | 2.17 | 5/16     |
| PBTS-5-250     | 5            | 250kcmil-6 | 4.85       | 1.91 | 2.17 | 5/16     |
| PBTS-6-250     | 6            | 250kcmil-6 | 5.75       | 1.91 | 2.17 | 5/16     |
| PBTS-7-250     | 7            | 250kcmil-6 | 6.64       | 1.91 | 2.17 | 5/16     |
| PBTS-8-250     | 8            | 250kcmil-6 | 7.53       | 1.91 | 2.17 | 5/16     |
| PBTS-9-250     | 9            | 250kcmil-6 | 8.42       | 1.91 | 2.17 | 5/16     |
| PBTS-10-250    | 10           | 250kcmil-6 | 9.32       | 1.91 | 2.17 | 5/16     |
| PBTS-11-250    | 11           | 250kcmil-6 | 10.21      | 1.91 | 2.17 | 5/16     |
| PBTS-12-250    | 12           | 250kcmil-6 | 11.10      | 1.91 | 2.17 | 5/16     |
| PBTS-13-250    | 13           | 250kcmil-6 | 12.00      | 1.91 | 2.17 | 5/16     |
| PBTS-14-250    | 14           | 250kcmil-6 | 12.89      | 1.91 | 2.17 | 5/16     |
| PBTS-2-350     | 2            | 350kcmil-6 | 2.51       | 2.03 | 2.62 | 5/16     |
| PBTS-3-350     | 3            | 350kcmil-6 | 3.56       | 2.03 | 2.62 | 5/16     |
| PBTS-4-350     | 4            | 350kcmil-6 | 4.61       | 2.03 | 2.62 | 5/16     |
| PBTS-5-350     | 5            | 350kcmil-6 | 5.66       | 2.03 | 2.62 | 5/16     |
| PBTS-6-350     | 6            | 350kcmil-6 | 6.71       | 2.03 | 2.62 | 5/16     |
| PBTS-7-350     | 7            | 350kcmil-6 | 7.76       | 2.03 | 2.62 | 5/16     |
| PBTS-8-350     | 8            | 350kcmil-6 | 8.81       | 2.03 | 2.62 | 5/16     |
| PBTS-9-350     | 9            | 350kcmil-6 | 9.86       | 2.03 | 2.62 | 5/16     |
| PBTS-10-350    | 10           | 350kcmil-6 | 10.91      | 2.03 | 2.62 | 5/16     |
| PBTS-11-350    | 11           | 350kcmil-6 | 11.96      | 2.03 | 2.62 | 5/16     |
| PBTS-12-350    | 12           | 350kcmil-6 | 13.01      | 2.03 | 2.62 | 5/16     |
| PBTS-13-350    | 13           | 350kcmil-6 | 14.06      | 2.03 | 2.62 | 5/16     |
| PBTS-14-350    | 14           | 350kcmil-6 | 15.11      | 2.03 | 2.62 | 5/16     |
| PBTS-2-500     | 2            | 500kcmil-4 | 2.97       | 2.28 | 3.04 | 3/8      |
| PBTS-3-500     | 3            | 500kcmil-4 | 4.12       | 2.28 | 3.04 | 3/8      |
| PBTS-4-500     | 4            | 500kcmil-4 | 5.28       | 2.28 | 3.04 | 3/8      |

Replacement caps &amp; plugs available. Consult Factory      Tested to UL 486A-486B, UL File E6207

