



Parallel Groove Clamps - Dual Rated

TYPE
PG

Features

- Manufactured from high strength 6061-T6 aluminum alloy
- Clear plated
- Range taking

Benefits

- Suitable for use with either copper or aluminum conductors
- Provides low contact resistance
- Permits inventories to be kept to a minimum

Rated for 600 Volts

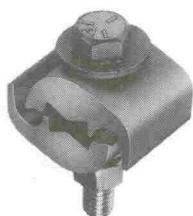
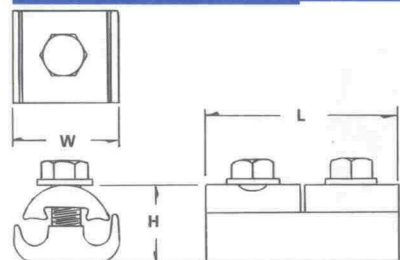


Fig. 1



Fig. 2

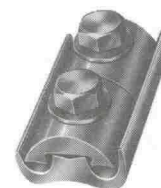


Fig. 3

C

Catalog Number	Figure Number	Wire Range Both Grooves	Type and Bolt Size	Dimensions		
				L	H	W
PG810-S-Z	1	1/0-8 Sol.	3/8, Steel	1-1/8	1-5/8	1-3/16
PG620-Z	2	2/0-6 Sol.	7/16, AL	1-3/8	1-5/8	1-1/4
PG620-A-Z	2	2/0-6 Sol.	3/8, AL	1-3/16	1-5/8	1-3/16
PG620-S-Z	2	2/0-6 Sol.	3/8, Steel	1-3/16	1-5/8	1-1/8
PG620-2A-Z	3	2/0-6 Sol.	3/8, AL	2-7/16	1-5/8	1-1/4
PG620-2S-Z	3	2/0-6 Sol.	3/8, Steel	2-7/16	1-5/8	1-1/4
PG402-S-Z	2	4/0-2	3/8, Steel	1-1/2	1-3/4	1-3/8
PG402-2S-Z	3	4/0-2	3/8, Steel	3-1/16	1-3/4	1-3/8

DE-OX Inhibitor is recommended for all aluminum terminations.