

# ILSCO Insulated Service Entrance Sleeves

**A**


## TYPE PICS

### Features

- Pre-insulated
- Concave polyethylene end caps
- Dual rated
- Meets ANSI C119.4 requirements
- RUS Listed
- Die Index 5/8 or BG

### Benefits

- Fast, easy installation
- Seal out dirt but are easily pierced when inserting conductor
- For use with aluminum-aluminum and aluminum-copper conductors
- Ensures reliability

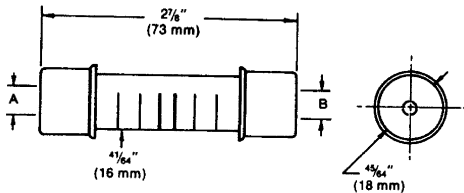

Catalog Number	End "A"					End "B"				
	Conductor Range				Color Code	Conductor Range				Color Code
	ACSR	AWG	Diameter			ACSR	AWG	Diameter		
max.			min.	max.	min.					
PICS-61	-	6 sol - 8 str	0.162	0.144	Green	-	6 sol - 8 str	0.162	0.144	Green
PICS-62	6	4 sol - 6 str	0.204	0.184	Blue	-	8 sol - 10 str	0.128	0.114	Brown
PICS-63	6	4 sol - 6 str	0.204	0.184	Blue	-	6 sol - 8 str	0.162	0.144	Green
PICS-64	6	4 sol - 6 str	0.204	0.184	Blue	6	4 sol - 6 str	0.204	0.184	Blue
PICS-65	4	2 sol - 3-4 str	0.258	0.213	Orange	-	8 sol - 10 str	0.128	0.114	Brown
PICS-66	4	2 sol - 3-4 str	0.258	0.213	Orange	-	6 sol - 8 str	0.162	0.144	Green
PICS-67	4	2 sol - 3-4 str	0.258	0.213	Orange	6	4 sol - 6 str	0.204	0.184	Blue
PICS-68	4	2 sol - 3-4 str	0.258	0.213	Orange	4	2 sol - 3-4 str	0.258	0.213	Orange
PICS-70	2	1-2 str	0.328	0.268	Red	-	6 sol - 8 str	0.162	0.144	Green
PICS-71	2	1-2 str	0.328	0.268	Red	6	4 sol - 6 str	0.204	0.184	Blue
PICS-72	2	1-2 str	0.328	0.268	Red	4	2 sol - 3-4 str	0.258	0.213	Orange
PICS-73	2	1-2 str	0.328	0.268	Red	2	1-2 str	0.328	0.268	Red
PICS-75	1/0	1/0	0.398	0.368	Yellow	6	4 sol - 6 str	0.204	0.184	Blue
PICS-76	1/0	1/0	0.398	0.368	Yellow	4	2 sol - 3-4 str	0.258	0.213	Orange
PICS-77	1/0	1/0	0.398	0.368	Yellow	2	2-1 str	0.328	0.268	Red
PICS-78	1/0	1/0	0.398	0.368	Yellow	-	1/0	0.398	0.368	Yellow

