


NBST Neutral Bar Adapter

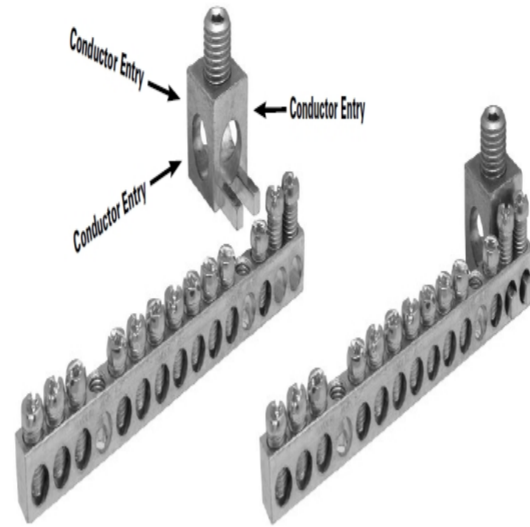

- Connects a 2/0-14 conductor to a neutral bar
 - Seamless stabs
 - Conductor entry at 90° or parallel to neutral bar
 - Mounts to solar nodes and neutral bars with hole spacing from .300" to .350"
 - Hex socket screw included
 - Manufactured from high strength aluminum
 - Electro-tin plated
 - UL 486 A/B and UL 467 Recognized, 90° C
 - Enables connection of a larger conductor for application versatility
 - Provide dual current path for reliability and cool operation
 - Multiple conductor orientation
 - For diverse field applications
 - Offers higher torque rating for reliability
 - Suitable for use with copper or aluminum conductors
 - Provides low contact resistance
 - For power and grounding applications
- All wire sizes, unless noted otherwise, are American Wire Gauge (AWG) DE-OX oxide inhibitor is recommended for all aluminum terminations

Item ID	Conductor Range	Length	Width	Height	Hex Size	Compatible IlSCO Neutral Bars	Compatible IlSCO Solar Nodes
NBST-2/0	2/0-14	1.140	0.700	0.780	3/16	NB-350 & NBAS	SCNL & SCNM