

Weatherproof Receptacle Covers

Weatherproof



WP1000C



WP1000HGC



WP1010C



WP1020C



WP1030C



WP1050



Guardian Series Weatherproof Plastic While-in-Use Covers

- Complies with 2008 NEC Article 406.8(B)
- Patented inserts offer more configurations and cover more jobs
- Two-gang models include inserts for Duplex or GFCI applications

Features:

- Single-gang covers packaged with three patented inserts for GFCI, duplex, toggle or round receptacles
- Inserts include keyhole slots for easy installation
- Pre-adhered gasket
- Heavy-duty polycarbonate construction
- Clear cover on most models. Two models with gray cover
- Meets requirements for cold impact testing at -60°F (-51°C)
- Max cord size for all covers: 2 – 14 gauge OR 1 – 12 gauge. Except WP1050: 2 – 14 gauge OR 1 – 10 gauge.

Warranty: Limited 1-year warranty

Model	Description	Depth	Color	Cord Diam. (in)	Exit Port Length (in)
WP1000C	Single-gang Vertical w/(WP17) Flexi-Guard Inserts	2¼ in.	Clear	0.5 in.	0.78
WP1000GC	Single-gang Vertical w/(WP17) Flexi-Guard Inserts	2¼ in.	Gray	0.5 in.	0.78
WP1000HC	Single-gang Horizontal w/(WP17) Flexi-Guard Inserts	2¼ in.	Clear	0.5 in.	0.78
WP1000HGC	Single-gang Horizontal w/(WP17) Flexi-Guard Inserts	2¼ in.	Gray	0.5 in.	0.78
WP1010C	Single-gang Vertical w/(WP17) Flexi-Guard Inserts	3⅞ in.	Clear	0.5 in.	0.78
WP1010HC	Single-gang Horizontal w/(WP17) Flexi-Guard Inserts	3⅞ in.	Clear	0.5 in.	0.78
WP1020C	Two-gang or Single-gang w/WP101 and WP102 Inserts	2¼ in.	Clear	0.5 in.	0.78
WP1030C	Two-gang or Single-gang w/WP101 and WP102 Inserts	3¼ in.	Clear	0.5 in.	0.78
WP1050	Two-gang or Single-gang w/WP101 and WP102 Inserts	4¼ in.	Clear	0.8 in.	1.27

Single-gang Flexi-Guard †



WP17 †

Two-gang products Include:

Two-gang Duplex




WP101

Two-gang GFCI



WP102

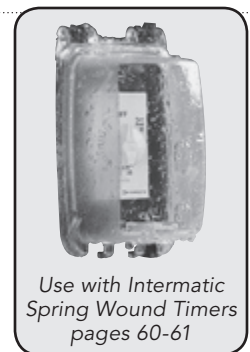

† Converts to toggle, 1⅜, 1⅝, 1¾ or 2⅛ in. diameter round.

Note: Lockable hasp accepts up to .125 in. (3.175 mm) diameter shank
See page 93 for insert information.