

Tool Sets




80014

603-4B	3' (76 mm) round-shank wire bending No. 2 Phillips cushion-grip screwdriver – 4" (102 mm) round-shank
605-4	1/4" cabinet-tip cushion-grip screwdriver – 4" (102 mm) heavy-duty round-shank
605-6	1/4" cabinet-tip cushion-grip screwdriver – 6" (152 mm) heavy-duty round-shank
670-6	3/16" cabinet-tip cushion-grip screwdriver – Rapi-Drive®
93025	25' x 1" tape measure
5164	8-pocket leather tool pouch
5225	adjustable web tool belt
11045	wire stripper/cutter – 10-18 AWG solid wire
60056	frameless protective eyewear

12-Piece Electrician Tool Set

Cat. No.	Set Contains	Weight (lbs.)
5300		6.82

Cat. No.	Description
5166	7-pocket leather tool pouch
5225	adjustable web belt
603-3	No. 1 Phillips cushion-grip screwdriver – 3" (76 mm) round-shank
603-4	No. 2 Phillips cushion-grip screwdriver – 4" (102 mm) round-shank
605-4	1/4" cabinet-tip cushion-grip screwdriver – 4" (102 mm) heavy-duty round-shank
605-6	1/4" cabinet-tip cushion-grip screwdriver – 6" (152 mm) heavy-duty round-shank
11045	wire stripper/cutter – 10-18 AWG solid wire
D248-8	high-leverage diagonal-cutting pliers – angled head
D203-8	heavy-duty long-nose pliers – side-cutting
D213-SNETP	high-leverage side-cutting pliers – fish tape pulling
D502-10	pump pliers with 1-3/4" (44 mm) jaw capacity
928-25HV	high-visibility power-return measuring tape

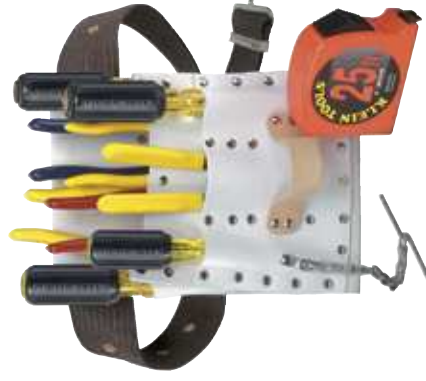

5300

All dimensions are in inches and (millimeters) unless otherwise specified.

⚠ WARNING: The tool belt provided in this kit is NOT an occupational protective belt.

⚠ WARNING: NOT insulated. Do NOT use these tools on or near live electrical circuits.

⚠ WARNING: Do NOT use screwdrivers to pry or chisel.

⚠ WARNING: Always wear approved eye protection.

⚠ WARNING: Do NOT open the tape measure case. Spring motor is under tension, and opening may cause injury.