


Screwdrivers, Nut Drivers & Accessories

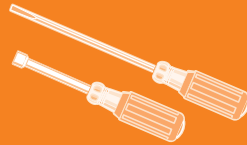

- Rotating cap for optimum and precise control.
- Klein Cushion-Grip handle for maximum comfort when working on small equipment.
- Professional custom carrying case included in set.
- Screwdrivers sold individually and in set (Cat. No. 85614).

NEW!



85614



Cat. No.	Set Contains	Weight
85614		.80 lbs. (0.36 kg.)

Cat. No.	Description	Blade Length	Overall Length
614-2	1/16" Slotted	2" (51 mm)	5-1/2" (140 mm)
613-3	#0 Phillips	3" (76 mm)	6-1/2" (165 mm)
614-3	3/32" Slotted	3" (76 mm)	6-1/2" (165 mm)
614-4	1/8" Slotted	4" (102 mm)	7-1/2" (191 mm)
614-6	1/8" Slotted	6" (152 mm)	9-1/2" (241 mm)

Miniature Screwdrivers

Additional Feature:

- Precision tip for exact fit and rigorous applications.



608-6

Cat. No.	Tip Type	Tip Size	Shank Length	Overall Length	Weight (lbs.)
604-3	Phillips-tip	#0	3" (76 mm)	5-3/4" (146 mm)	.04
606-2	Keystone-tip	1/16" (1.6 mm)	2" (51 mm)	4-3/4" (121 mm)	.03
607-2	cabinet-tip	3/32" (2.4 mm)	2" (51 mm)	4-3/4" (121 mm)	.03
607-3	cabinet-tip	3/32" (2.4 mm)	3" (76 mm)	5-3/4" (146 mm)	.04
607-4	cabinet-tip	3/32" (2.4 mm)	4" (102 mm)	6-3/4" (171 mm)	.04
608-2	cabinet-tip	1/8" (3.2 mm)	2" (51 mm)	4-3/4" (121 mm)	.03

Cat. No.	Tip Type	Tip Size	Shank Length	Overall Length	Weight (lbs.)
608-3	cabinet-tip	1/8" (3.2 mm)	3" (76 mm)	5-3/4" (146 mm)	.04
608-4	cabinet-tip	1/8" (3.2 mm)	4" (102 mm)	6-3/4" (171 mm)	.05
608-6	cabinet-tip	1/8" (3.2 mm)	6" (152 mm)	8-3/4" (222 mm)	.05
608-8	cabinet-tip	1/8" (3.2 mm)	8" (203 mm)	10-3/4" (273 mm)	.05
608-10	cabinet-tip	1/8" (3.2 mm)	10" (254 mm)	12-3/4" (324 mm)	.05

Coated Cabinet-Tip Screwdrivers – Round-Shanks

Additional Features:

- Plastic coated for circuit protection only. NOT INSULATED.
- Special plastic coating resists cutting, cracking and chipping.
- Thin coating permits use in confined areas.



620-4

Cat. No.	Tip Size	Shank Length	Overall Length	Weight (lbs.)
620-3	3/16" (5 mm)	3" (76 mm)	6-3/4" (171 mm)	.15
621-6	3/16" (5 mm)	6" (152 mm)	9-3/4" (248 mm)	.20
621-8	3/16" (5 mm)	8" (203 mm)	11-3/4" (298 mm)	.20
621-10	3/16" (5 mm)	10" (254 mm)	13-3/4" (349 mm)	.25

Cat. No.	Tip Size	Shank Length	Overall Length	Weight (lbs.)
Heavy-Duty Shanks				
620-4	1/4" (6 mm)	4" (102 mm)	8-11/32" (212 mm)	.20
620-6	5/16" (8 mm)	6" (152 mm)	10-15/16" (278 mm)	.40
620-8	3/8" (10 mm)	8" (203 mm)	13-7/16" (341 mm)	.60

Square-Recess Tip Screwdrivers – Round-Shanks

Additional Features:

- Color-coded handle ends for quick and easy identification.
- Round shank with Square-Recess tip.



660