


Cushion-Grip Nut Drivers

Magnetic Tip Nut Drivers - Hollow Shafts*

Additional Feature:

- Exclusive hollow shaft* design with Rare Earth magnetic tip features unobstructed pass-through, even on long bolts.

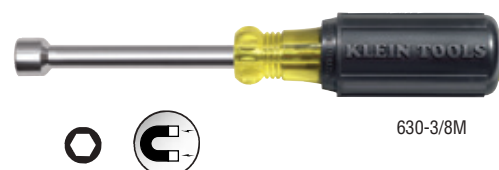

630-3/8M

Cat. No.	Color Code	Hex Size	Shaft Length	Overall Length	Weight (lbs.)
610-1/4M	red	1/4"	3" (76 mm)	1-1/2" (89 mm)	.10
610-5/16M	yellow	5/16"	3" (76 mm)	1-1/2" (89 mm)	.10
610-3/8M	blue	3/8"	3" (76 mm)	1-1/2" (89 mm)	.10
630-3/16M*	black	3/16"	3" (76 mm)	6-3/4" (171 mm)	.20
630-1/4M	red	1/4"	3" (76 mm)	6-3/4" (171 mm)	.20
630-5/16M	yellow	5/16"	3" (76 mm)	6-3/4" (171 mm)	.20
630-11/32M	green	11/32"	3" (76 mm)	6-3/4" (171 mm)	.20
630-3/8M	blue	3/8"	3" (76 mm)	6-3/4" (171 mm)	.20
630-7/16M	brown	7/16"	3" (76 mm)	7-5/16" (186 mm)	.25
630-1/2M	red	1/2"	3" (76 mm)	7-5/16" (186 mm)	.25

Cat. No.	Color Code	Hex Size	Shaft Length	Overall Length	Weight (lbs.)
646-3/16M*	black	3/16"	6" (152 mm)	9-3/4" (248 mm)	.25
646-1/4M	red	1/4"	6" (152 mm)	9-3/4" (248 mm)	.25
646-5/16M	yellow	5/16"	6" (152 mm)	9-3/4" (248 mm)	.25
646-11/32M	green	11/32"	6" (152 mm)	9-3/4" (248 mm)	.25
646-3/8M	blue	3/8"	6" (152 mm)	9-3/4" (248 mm)	.30
646-7/16M	brown	7/16"	6" (152 mm)	10-5/16" (262 mm)	.35
646-1/2M	red	1/2"	6" (152 mm)	10-5/16" (262 mm)	.35
618-1/4M	red	1/4"	18" (457 mm)	21-3/4" (552 mm)	.50
618-5/16M	yellow	5/16"	18" (457 mm)	21-3/4" (552 mm)	.50

*3/16" magnetic nut driver does not have a hollow shaft.

Drive-A-Matic Cushion-Grip Nut Driver



632

Additional Features:

- Automatically fits 15 different nut and screw sizes.
- Hex head adjusts to the proper size as you turn it.
- Will drive or loosen hex nuts from 1/4" (6.4 mm) to 7/16" (11.1 mm), hex-head screws from No. 6 to 1/4" (6.4 mm), and socket-head cap screws from No. 8 to 5/16" (7.9 mm).

Cat. No.	Overall Length	Weight (lbs.)
632	7" (178 mm) when open, 6-3/4" (171 mm) when closed	.35

Coated Hollow-Shaft Nut Drivers



640-1/2

Additional Features:

- Entire shaft plastic coated for circuit protection only. NOT INSULATED.
- Special plastic coating resists cutting, cracking and chipping.
- Thin coating permits use in confined areas.

Cat. No.	Color Code	Hex Size	Shaft Length	Overall Length	Weight (lbs.)
640-3/16	black	3/16"	3" (76 mm)	6-3/4" (171 mm)	.25
640-1/4	red	1/4"	3" (76 mm)	6-3/4" (171 mm)	.25
640-5/16	yellow	5/16"	3" (76 mm)	6-3/4" (171 mm)	.25
640-3/8	blue	3/8"	3" (76 mm)	6-3/4" (171 mm)	.25
640-7/16	brown	7/16"	3" (76 mm)	7-5/16" (186 mm)	.30
640-1/2	red	1/2"	3" (76 mm)	7-5/16" (186 mm)	.25
640-9/16	orange	9/16"	4" (102 mm)	9-3/8" (238 mm)	.40
640-5/8	yellow	5/8"	4" (102 mm)	9-3/8" (238 mm)	.40

⚠ WARNING: NOT insulated. Coating is intended for protection of circuits only.



All dimensions are in inches and (millimeters).

⚠ WARNING: Always wear approved eye protection.

⚠ WARNING: NOT insulated. Will NOT protect against electrical shock.

