

Bolt Cutters

Bolt Cutters – Heavy-Duty



63536

- Designed for constant use in the most demanding applications.
- Heavy-duty side plates keep jaws aligned for clean, quick cuts through reinforcing rod, wire mesh, guy strand, and many other materials too tough for standard bolt cutters.
- Steel handles and precision ground, forged alloy tool steel jaws.
- Lever design creates 4,000 lbs. jaw pressure with 50 lbs. hand pressure.
- Handles have heavy vinyl grips with flat grip ends for 90° cuts.

Steel Handles					
Cat. No.	Overall Length	Soft & Medium Cutting Maximum Capacities*	Hard Material Cutting Maximum Capacities**	Handle Color	Weight (lbs.)
63524	24" (610 mm)	7/16" (11 mm)	5/16" (8 mm)	red	7.10
63530	30" (762 mm)	1/2" (13 mm)	3/8" (10 mm)	red	11.65
63536	36" (914 mm)	9/16" (14 mm)	7/16" (11 mm)	red	16.35
63542	42" (1067 mm)	11/16" (18 mm)	1/2" (13 mm)	red	21.00

* Up to Brinell 300, Rockwell C31.

** Up to Brinell 400, Rockwell C42.


Replacement Bolt Cutter Heads (complete)		
Cat. No.	Fits Cat. No.	Weight (lbs.)
63636	63536	6.50
63642	63542	8.70

Cable Benders



50400

- Forged, one-piece steel construction for exceptional durability and high strength to meet the most demanding job requirements.
- Head is angled 22° for ease in bending cable in tight, hard-to-access places.
- Corrosion-resistant, black-oxide finish with heavy-duty double-dipped plastic handle.
- Handle is contoured for a firm, comfortable grip.
- It is recommended that two benders be used for easier bends.

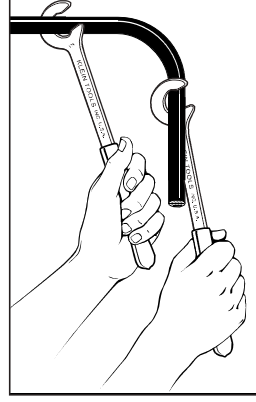

Cat. No.	Overall Length	Tool Opening	Maximum Cable Capacity	Weight (lbs.)
50400	12" (305 mm)	7/8" (22 mm)	350 MCM	.90
50402	14-1/2" (367 mm)	1-1/64" (26 mm)	500 MCM	1.55

