


Long-Arm Hex-Keys – Inch

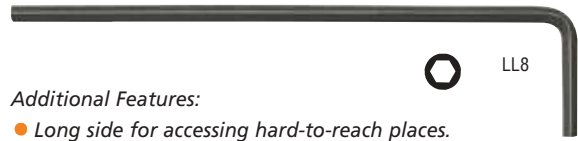


Additional Features:

- Long side for accessing hard-to-reach places.
- Short side for higher torque situations and low clearances.

Cat. No.	Hex Size	Size and Length		Weight (lbs.)
		Short Arm Length	Long Arm Length	
LL2	.050"	5/8"	2-15/16"	.005
LL4	1/16"	21/32"	3-3/32"	.005
LL5	5/64"	11/16"	3-9/32"	.005
LL6	3/32"	3/4"	3-15/32"	.01
LL7	7/64"	25/32"	3-21/32"	.02
LL8	1/8"	27/32"	3-27/32"	.02
LL9	9/64"	7/8"	4-1/32"	.03
LL10	5/32"	15/16"	4-7/32"	.03
LL12	3/16"	1-1/32"	4-1/2"	.05
LL14	7/32"	1-1/8"	4-29/32"	.70
LL16	1/4"	1-7/32"	5-11/32"	.10
LL20	5/16"	1-11/32"	6-1/32"	.18
LL24	3/8"	1-15/32"	6-27/32"	.25

Long-Arm Hex-Keys – Metric

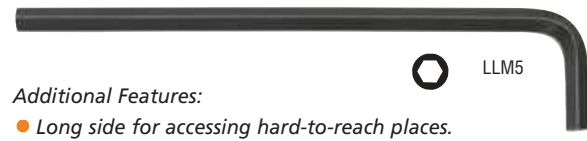

Additional Features:

- Long side for accessing hard-to-reach places.
- Short side for higher torque situations and low clearances.

Cat. No.	Hex Size	Size and Length		Weight (lbs.)
		Short Arm Length	Long Arm Length	
LLM15	1.5 mm	17/32"	3-1/32"	.005
LLM2	2 mm	13/32"	3-7/32"	.005
LLM25	2.5 mm	11/16"	3-15/32"	.01
LLM3	3 mm	3/4"	3-7/8"	.02
LLM4	4 mm	15/16"	4-3/32"	.03
LLM5	5 mm	1-1/16"	4-9/16"	.05
LLM6	6 mm	1-7/32"	5-7/16"	.08
LLM8	8 mm	1-3/8"	6-3/16"	.15
LLM10	10 mm	1-17/32"	6-9/16"	.25

⚠WARNING: Do NOT use a pipe or similar extension to increase leverage on L-Style Hex-Keys.

T-Handle Hex-Key Sets

Features:

Color-coded handles:
blue for metric,
black for inch.

Molded-in finger grooves
for comfort.



Cat. No. and hex size on handle
for positive identification.

Treated steel for
rust and corrosion
resistance.

T-handle design delivers
more torque to the fasteners.

9" length is available for
hard-to-reach applications.



T-Handle Hex-Keys

Additional Features:

- T-handle design delivers more torque to the fasteners.
- Color-coded handles: blue for metric, black for inch.



6" Length – Inch

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
76209	9/64"	4" (102 mm)	.08
76214	7/32"	4-1/2" (114 mm)	.19

9" Length – Inch

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
79206	3/32"	7-1/4" (184 mm)	.07
79209	9/64"	7-1/4" (184 mm)	.09
79212	3/16"	7-1/2" (191 mm)	.19
79216	1/4"	7-1/2" (191 mm)	.26
79224	3/8"	7-1/2" (191 mm)	.45

6" Length – Metric

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
76302	2 mm	6" (152 mm)	.06
76325	2.5 mm	6" (152 mm)	.07
76306	6 mm	6" (152 mm)	.22
76308	8 mm	6" (152 mm)	.31
76310	10 mm	6" (152 mm)	.42

⚠WARNING: Always wear approved eye protection.

⚠WARNING: NOT insulated. Will NOT protect against electrical shock.

