







88 01 180 KNIPEX Alligator®

Water Pump Pliers



- Technical details
- Description
- Applications
- PDF


No.	88 01 180	
EAN	4003773035480	
Pliers	black atramentized	
Head	polished	
Handles	with non-slip plastic coating	
Adjustment positions	9	
Nominal size	180 mm	
	1 1/2	Ø Inch
	36	mm
	42	Ø mm
	180	mm
	180	g
	180	g

- more output and comfort compared to conventional water pump pliers of the same length: 9-notch adjustment positioning for 30 % more gripping capacity
- good access to the workpiece due to slim size in the head and joint area
- self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: low wear and stable gripping
- box-joint design: high stability because of double guide
- robust construction, insensitive to dirt; particularly suitable for outdoor work
- guard prevents operators' fingers being pinched
- Chrome vanadium electric steel, forged, oil-hardened



Self-locking on pipes and nuts: no slipping on the workpiece; the complete actuating force can be used to turn the workpieces; not having to squeeze the pliers handles reduces the required effort



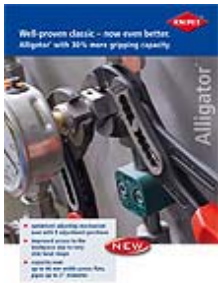

Product Information Alligator® 88
technical change and errors excepted