

13 81 8 Installation Pliers






- Technical details
- Description
- Applications

	No.	13 81 8	
	EAN	843221019969	
	Pliers	black atramentized	
	Head	polished	
	Handles	plastic coated	
	Cu cable, fine-stranded	19/32	Ø Inch
	Cu + Al multi-conductor cable, strand and multi-stranded	0	AWG
	Stripping capacity for cross-sections	12 + 14	AWG
	Crimping capacity	12 - 20	AWG
	Net weight	285	g
	Length	200	mm

- multifunctional pliers for the electrical installation; to grip flat and round material, for bending, deburring, cutting cable, stripping and crimping end sleeves (ferrules)
- 6 functions in one pair of pliers
- smooth surfaces near the tips grip single conductors without damaging them; serrated gripping surfaces and pipe grip for gripping flat and round material
- clear-cut outside edge on the jaw for working on flush-mounted junction boxes and deburring feed-through holes

- stripping holes for 12 + 14 AWG (0.7 - 1.5 mm² and 2.5 mm²)
- crimp die for end sleeves (ferrules) 12 - 20 AWG (0.5 - 2.5 mm²)
- cable shears with (induction-hardened) precision cutting edges for copper and aluminium cables up to 19/32" dia. (5 x 2.5 mm² / dia. 5 mm)
- slim dimensions for easy access
- bolted joint: precise, zero-backlash operation of pliers
- High-grade special tool steel; forged, oil-hardened

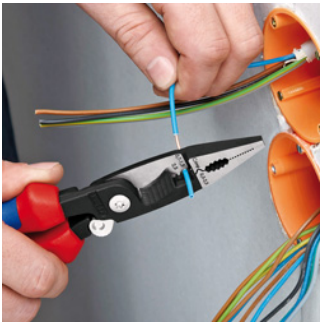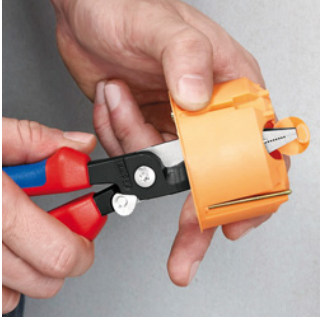

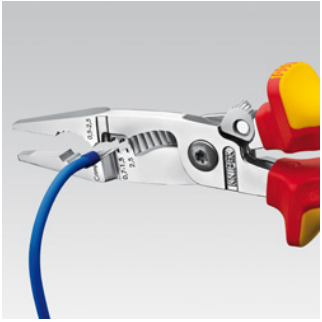

technical change and errors excepted