


EPIC® HB 10 Standard Hoods

Single Lever Bolts

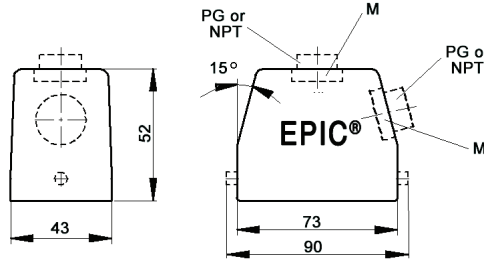

All dimensions are in mm.

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry		PG	Part Number		Complete the Installation: SKINTOP® Strain Relief, page 368			
	NPT	Metric		NPT	Metric	PG Nylon	PG Metal	Metric Nylon	Metric Metal
Top Entry									
16	1/2"	20	100409	100409NP	19040900*	53015040	52015740	53111020	53112020
21	3/4"	25	100407	100407NP	19040700*	53015050	52015750	53111030	53112030
Side Entry									
16	1/2"	20	100429	100429NP	19042900	53015040	52015740	53111020	53112020
21	3/4"	25	100428	100428NP	19042800	53015050	52015750	53111030	53112030

* Metric top-entry hoods do not come with a neck.

Approvals




Complete the Installation



HB Dust Covers:
page 415

EPIC® HB 10 High Profile Hoods

Single Lever Bolts

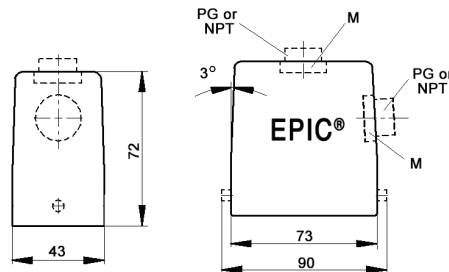

All dimensions are in mm.

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry		PG	Part Number		Complete the Installation: SKINTOP® Strain Relief, page 368			
	NPT	Metric		NPT	Metric*	PG Nylon	PG Metal	Metric Nylon	Metric Metal
Top Entry									
21	3/4"	25	700442	700442NP	79044200	53015050	52015750	53111030	53112030
29	1"	32	700444	700444NP	79044400	53015060	52015760	53111040	53112040
Side Entry									
21	3/4"	25	700542	700542NP	79054200	53015050	52015750	53111030	53112030
29	1"	32	700544	700544NP	79054400	53015060	52015760	53111040	53112040

* Metric hoods do not come with a neck.

Approvals



Complete the Installation



HB Dust Covers:
page 415

Photographs are not to scale and are not true representations of the products in question. For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.