

NAVIGATE THE CATALOG BY SECTIONS

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18
- 19
- 20
- 21
- 22

Product Chapter Finder "Flip" Catalogs: Advanced Product Searches:


EPIC®

HB Series

Rectangular Connector Housings

EPIC® HB 10 Standard Hoods

Double Lever Bolts

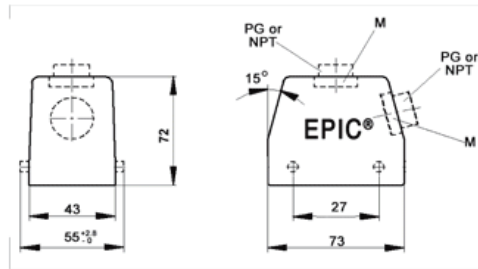

All dimensions are in mm.



Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

Size of Entry	PG		Part Number	Metric		Complete the Installation: SKINTOP® Strain Relief, page 368			
	NPT	Metric		NPT	Metric	PG Nylon	PG Metal	Metric Nylon	Metric Metal
Top Entry									
16	1/2"	20	100400	100400NP	19040000*	53015040	52015740	53111020	53112020
21	3/4"	25	100401	100401NP	19040100	53015050	52015750	53111030	53112030
Side Entry									
16	1/2"	20	100420	100420NP	19042000	53015040	52015740	53111020	53112020
21	3/4"	25	100421	100421NP	19042100	53015050	52015750	53111030	53112030

* Metric top-entry hoods do not come with a neck.

Approvals




Complete the Installation



HB Dust Covers:
page 415

EPIC® HB 10 High Profile Hoods

Double Lever Bolts

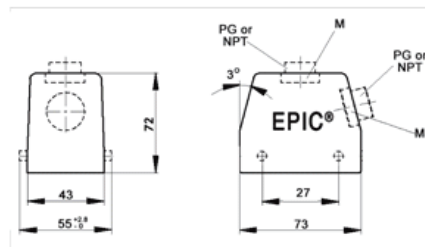

All dimensions are in mm.



Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
-----------------	-----------	-------------------	-----------------------