





Pass &amp; Seymour

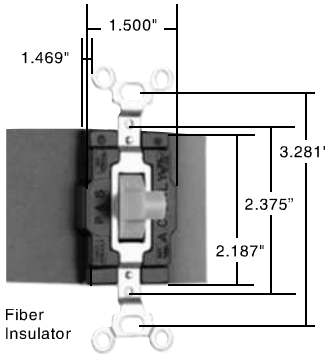

Maintained and Momentary Contact

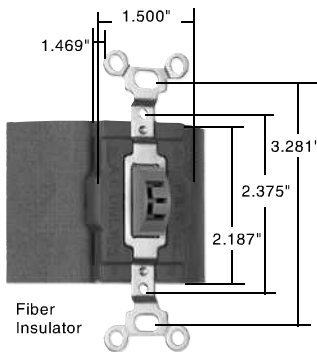

Locking

## Switches Manual Controllers

15, 20 &amp; 30A, 120/277VAC – Maintained Contact

15, 20 &amp; 30A, 120/277VAC – Momentary Contact

### Applications

For ON-OFF control of motors on small machine tools, pumps, fans and air conditioning equipment that require heavy-duty AC Double Throw Center OFF controls.

### Features

- Oversized silver alloy contacts for long life and better heat dissipation.
- Side wired terminals accept #14 – #10 AWG copper or copper-clad conductors.
- Fiber terminal insulation barriers standard.
- Can be mounted in standard device boxes or in NEMA 1 sheet steel enclosures.
- Bodies, covers and toggles molded of durable nylon.
- Single Pole-Double Throw and Double Pole-Double Throw.
- Locking Switches supplied with one 1498 NT key.
- Normally open.

Catalog Number		Rating		Color
S.P.D.T.	D.P.D.T.	A.	VAC	
<b>Maintained Contact Three Position – Two Circuit, Center Off</b>				
1221I	1222I	15	120/277	Ivory White Brown Light Almond Locking
1221W	1222W	15	120/277	
1221	1222	15	120/277	
1221LA		15	120/277	
1221L	1222L	15	120/277	
1225I	1226I	20	120/277	
1225W	1226W	20	120/277	
1225	1226	20	120/277	
1225GRY		20	120/277	
1225LA		20	120/277	
1225L	1226L	20	120/277	
1227I	1228I	30	120/277	Ivory Brown
1227	1228	30	120/277	
<b>Maintained Contact Either Direction Two Position, No Center Off</b>				
1275	1276	30	120/277	Brown
<b>Momentary Contact Either Direction Three Position, Center Off</b>				
1250I		15	120/277	Ivory White Brown Gray Red Locking
1250W		15	120/277	
1250		15	120/277	
1250GRY		15	120/277	
1250RED		15	120/277	
1250L		15	120/277	
1251I		20	120/277	Ivory White Brown Gray Light Almond Locking
1251W		20	120/277	
1251		20	120/277	
1251GRY		20	120/277	
1251LA		20	120/277	
1251L		20	120/277	
	1256I	30	120/277	Ivory White Brown Locking
1255	1256W	30	120/277	
1255L	1256	30	120/277	
	1256L	30	120/277	

### Catalog Number

### Description

### Lock Switch Replacement Keys

1498

Fits switches manufactured before 1976.

1498NT

Fits switches manufactured between 1976-present.

### HP Conversion Table

1221 Series		1250 Series	
15 Amp	1/2 Horsepower at 120VAC 2 Horsepower at 240VAC	15 Amp	1/2 Horsepower at 120VAC 2 Horsepower at 240VAC
20 Amp	1 Horsepower at 120VAC 2 Horsepower at 240VAC	20 Amp	1 Horsepower at 120VAC 2 Horsepower at 240VAC
30 Amp	2 Horsepower at 120VAC 2 Horsepower at 240VAC	30 Amp	2 Horsepower at 120VAC 2 Horsepower at 240VAC

UL Listed.  
CSA Certified.  
All devices listed on this page conform to NEMA WD-1 and WD-6.

# Switches PlugTail™ Specification Grade Decorator Switches

**legrand®**  
Pass & Seymour

Switches

**Auto-ground clip**  
assures positive ground.

**Shallow design**  
for easier installation.

**Heavy-gauge steel strap** for superior strength.

**No exposed terminals** create a finger-safe application before, during, and after installation.




**Built-in connector** features large brass terminal blades to ensure consistent, reliable electrical connections.

**Large brass contacts** snugly terminate on device blade terminals. Audible snapping latch assures connection, allows release.

**Polycarbonate connector housing** secures terminations and conductors in a UL Listed, finger-safe housing.

**WAGO push-in connectors** are available to further speed up installation.

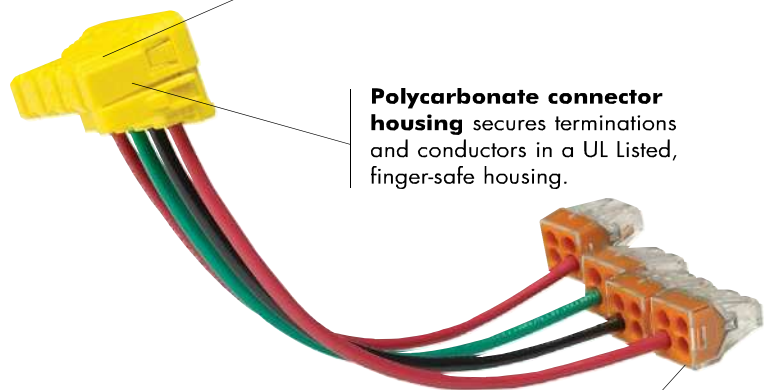

**PT2626W**

PlugTail™ Spec Grade Decorator Switches