



designed to be better.

# Audible Alarm Tamper-Resistant GFCI Receptacle, White

1595TRAW

Audible Alarm Tamper-Resistant GFCI Receptacle notifies end user of tripped GFCI. Provides supplemental notification (along w/Trip Indicator Light). Listed 10kA SCCR, 15A 125VAC, White

Where to buy

Like




•



•



•

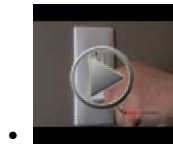

## product gallery

Representative images shown.

### AVAILABLE OPTIONS



Audible Alarm Tamper-Resistant GFCI Receptacle, Brown



Audible Alarm Tamper-Resistant GFCI Receptacle, Black



Audible Alarm Tamper-Resistant GFCI Receptacle, Ivory








Audible Alarm Tamper-Resistant GFCI Receptacle, Light Almond

- SPECIFICATIONS
- RESOURCES

## features & benefits

- **Patented SafeLock™ Protection for More Safety** - shuts off power to the receptacle if there's a ground fault, if the GFCI is miswired, and even if the GFCI fails. This prevents the unsafe condition of power without protection.
- **Tamper-Resistant: Automatic shutter system** prevents young children from inserting common objects such as hairpins or keys.
- **The most durable GFCI available** - exceeds UL943 voltage surge requirements; survives 100x the required UL 3kA/6kV voltage surge test cycles.
- **Audible Alarm notifies end user of tripped GFCI**. Provides Supplemental notification (along w/Trip Indicator Light - red LED). Alarm can be turned on/off.
- **Side or internal screw-pressure-plate back wire termination** speeds installation; takes #14 – #10 AWG stranded or solid, copper or copperclad conductors.
- **Two back-wire holes per termination** add wiring flexibility, eliminate pigtailing, and save box space.
- **Ground terminal back-wire clamp** for fast installation.
- **High-impact-resistant thermoplastic construction** for superior strength and durability.

## Top 5 Resources

-  [Audible Alarm GFCI \(Sell Sheet\)](#)
-  [Better Living Upgrades \(Brochure\)](#)
-  [GFCI Test & Protect \(Brochure\)](#)
-  [Tamper-Resistant Receptacles \(Brochure\)](#)
-  [Commercial & Industrial Products \(Brochure\)](#)

## specifications

### General Info

- Color: White
- Type: Audible Alarm GFCI Receptacle
- Special Features: Tamper Resistant
- Style: Decorator

### Listing Agencies/Third Party Information

- CSA Listing Info: No

- CUL Listing No: No
- cU Lus: Yes
- Federal Spec: No
- UL Listing No: No
- U N SPS C: 39121614
- U R: No

## Dimensions

- Depth (U S): 1.13"
- Height U S: 4.2"
- Width U S: 1.72"

## Technical Information






- Amps: 15 Amp
- Volts: 125
- Volts A C: 125

## Buy American Act Compliance


- Country of Origin: MEXICO
- Buy American Act Status: Trade Agreement Act Compliant
- 



## resources BROCHURE

-  Better Living UpgradesPDF (1.2mb)
-  GFCI Test & ProtectPDF (494.1kb)
-  Tamper-Resistant ReceptaclesPDF (791.69kb)
-  Commercial & Industrial ProductsPDF (3.52mb)
-  GFCI ReceptaclesPDF (1.19mb)




## CUTSHEET

-  Spec Grade GFCIs, SF1101R4PDF (394.6kb)

## SELL SHEET

-  Audible Alarm GFCIPDF (763.88kb)

## INSTALLATION INSTRUCTIONS

-  GFCI ReceptaclePDF (109.09kb)
-  Instalación y prueba de un tomacorriente GFCIPDF (639.9kb)
-  Installation et test d'une prise DDFTPDF (208.23kb)