




designed to be better.

 Search

Hospital Grade GFCI Receptacle, Ivory

2095HGI

GFCI Hospital Grade Receptacle, 10kA SCCR, 20A 125VAC, Ivory

Submit Query


Where to buy

Submit Query

Like

Tweet

 
Email Print

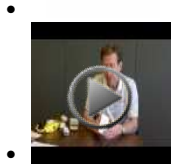



product gallery

Representative images shown.

AVAILABLE OPTIONS



Hospital Grade 20 Amp Duplex GFCI, White



Hospital Grade GFCI Receptacle, Brown



Hospital Grade GFCI Receptacle, Black



Hospital Grade GFCI Receptacle, Gray



Hospital Grade GFCI Receptacle, Light Almond








Hospital Grade GFCI Receptacle, Red

- SPECIFICATIONS
- RESOURCES

features & benefits

- **Patented SafeLock™ Protection for More Safety** - shuts off power to the receptacle if there's a ground fault, if the GFCI is miswired, and even if the GFCI fails. This prevents the unsafe condition of power without protection.
- **Tamper-Resistant: Automatic shutter system** prevents young children from inserting common objects such as hairpins or keys.
- **The most durable GFCI available** - exceeds UL943 voltage surge requirements; survives 100x the required UL 3kA/6kV voltage surge test cycles.
- **Audible Alarm notifies end user of tripped GFCI.** Provides Supplemental notification (along w/Trip Indicator Light - red LED). Alarm can be turned on/off.
- **Side or internal screw-pressure-plate back wire termination** speeds installation; takes #14 – #10 AWG stranded or solid, copper or copperclad conductors.
- **Two back-wire holes per termination** add wiring flexibility, eliminate pigtailing, and save box space.
- **Ground terminal back-wire clamp** for fast installation.
- **High-impact-resistant thermoplastic construction** for superior strength and durability.

Top 5 Resources

-  [GFCI Test & Protect \(Brochure\)](#)
-  [GFCI Receptacles \(Brochure\)](#)
-  [Hospital Grade GFCIs Spec Sheet, SF708R3 \(Cutsheet\)](#)
-  [GFCI Receptacle \(Installation Instructions\)](#)
-  [Instalación y prueba de un tomacorriente GFCI \(Installation Instructions\)](#)

specifications

General Info

- Color: Ivory
- Type: GFCI Receptacle
- Style: Decorator

Listing Agencies/Third Party Information

- CSA Listing Info: C22.2 No.42 & 144
- CSA Standard: Yes

- CUL Listing No: UL943, UL498
- cU Lus: Yes
- cUL Standard: Yes
- cU Rus: No
- Federal Spec: Yes
- Fed Spec Number: WC596
- UL Listing No: UL943, UL498
- UL Standard: Yes
- U N SPS C: 39121614
- U R: No

Dimensions

- Depth (U S): 0.98"
- Height U S: 4.2"
- Width U S: 1.72"



Technical Information

- Amps: 20 Amp
- Volts: 125
- Volts A C: 125
- Grade Type: Hospital


Buy American Act Compliance

- Country of Origin: CHINA
- Buy American Act Status: No
-




resources BROCHURE

-  [GFCI Test & ProtectPDF \(494.1kb\)](#)
-  [GFCI ReceptaclesPDF \(1.19mb\)](#)

CUTSHEET

-  [Hospital Grade GFCIs Spec Sheet, SF708R3PDF \(375.45kb\)](#)

INSTALLATION INSTRUCTIONS

-  [GFCI ReceptaclePDF \(109.09kb\)](#)
-  [Instalación y prueba de un tomacorriente GFCIPDF \(639.9kb\)](#)
-  [Installation et test d'une prise DDFTPDF \(208.23kb\)](#)