

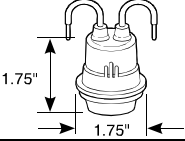
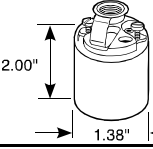
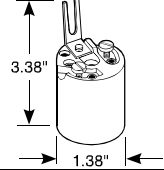
 

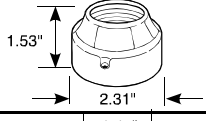
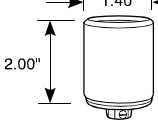
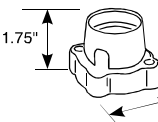
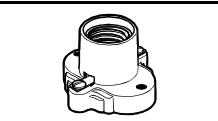



# Electrical Accessories Incandescent Lampholders



Metal Shell Lampholders							
Catalog Number	Rating	Description	Color	UL	CSA	cULus	
975ABDCC10	660W 250V	Medium base, metal shell, keyless.		•	•		
Medium Base Lampholders							
8101	660W 250V	Medium base, porcelain, keyless, single circuit, 2 piece ring with leads. 1-3/8" to 1-1/2" hole.	White	•			
201	660W 600V	Medium base, rubber, keyless, for temporary lighting, 2 wire leads 6" long.	Black	•		•	
31528	660W 250V	Medium base, porcelain, screw terminals, keyless, single circuit, fixture pan with 1/8" IPS hickey.	White	•	•		
3352F	660W 250V	Medium base, porcelain, keyless, screw terminals, short base.	White	•	•		
8052CC10	660W 250V	Medium base, porcelain, bracket mount.		•	•		
9814	250W 250V	Medium base, porcelain, 2-piece pull chain, ring type, screw terminals, gasket furnished.	White				
9880	660W 250V	Medium base, porcelain, surface mount type, 2-piece.	White	•	•		
10045	660W 250V	Medium base, porcelain, keyless, single circuit with screw terminals, aluminum screw shell with set.	White	•	•		
10085	660W 250V	Medium base, porcelain, keyless, single circuit with 2-18 AWG leads 6" long.	White	•	•		
19062	660W 250V	Medium base, porcelain, pony cleat type, terminal screws.	White	•	•		
S752WCC10	660W 250V	Medium base, cleat sockets, front wire.	White			•	
61	660W 125V	Medium base, outlet to lampholder, 2 Pole, 2 Wire.	Brown				