

9zdXJlcyld2lkdGg9ljlxOClgaGVpZ2h0PSIxMTIiIC8+ZAIFDw8WAh8EBTQvd2lyZS1jYWJsZS1tYW5hZ2VtZW50L3dpcmVsZXNzLXpvbmUtZW5jbG9zdXJlcy5



designed to be better.

Search

TradeMaster Tamper-Resistant Receptacle

3232TRI


Tamper-Resistant Duplex Grounding Receptacle meets 2008 National Electrical Code Tamper-Resistant requirements. It protects children with its patented shutter system that helps prevent improper insertion of foreign objects. It is made with a high-impact resistant thermoplastic construction. 15 amp, 125 volt. Ivory.

Submit Query

Where to buy

Submit Query

Like 0 Tweet 0 0 Email Print

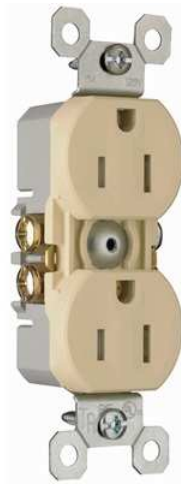

-
-
-



•



•

product gallery

Representative images shown.

AVAILABLE OPTIONS



TradeMaster Tamper-Resistant Receptacle



TradeMaster Tamper-Resistant Receptacle



TradeMaster Tamper-Resistant Receptacle



TradeMaster Tamper-Resistant Receptacle

- SPECIFICATIONS
- YOU MIGHT LIKE
- RESOURCES

features & benefits

- Meets 2008 National Electrical Code Tamper-Resistant requirements.
- Protects children: patented shutter system helps prevent improper insertion of foreign objects.
- High-impact resistant thermoplastic construction.
- Extra-long strap.
- Quickloop wire looping aid.
- Long-term blade retention.
- Longer tri-drive screws for easier 12 AWG looping.
- Extra-large circuit break-off tabs.
- Side-access push wire release.
- Ultrasonic welding of face to back body.
- Side wire accepts #12 – #14 AWG solid wire.
- Push wire accepts #14 AWG solid only.
- Superior protection than traditional outlet caps or protection plates.
- Low profile face.
- Traditional contoured face (3232 models).
- Self-grounding models provide automatic ground clip.

Top 5 Resources

-  Tamper-Resistant Receptacles (Brochure)

specifications

General Info

- Color: Ivory
- Type: Tamper-Resistant

Listing Agencies/Third Party Information

- CSA Listing Info: C22.2 No.42
- CSA Standard: Yes
- cULus: Yes
- Federal Spec: No
- UL Listing No: UL498
- UL Standard: Yes
- U N SPS C: 39121406

Dimensions

- Depth (U S): 1"
- Height U S: 3.31"
- Width U S: 1.32"

Technical Information

- Amps: 15 Amp
- Volts A C: 125

Buy American Act Compliance

- Country of Origin: CHINA
- Buy American Act Status: No
-

you might like




2000TR Series Tamper-Resistant Multioutlet System

2000TR

[View Details](#)

resources

BROCHURE

 [Tamper-Resistant ReceptaclesPDF \(791.69kb\)](#)