



designed to be better.


# TradeMaster Tamper-Resistant Receptacle

3232TR

Tramper-Resistant Duplex Grounding Receptacle. 15 amp, 125 volt. Brown.

Where to buy

Like

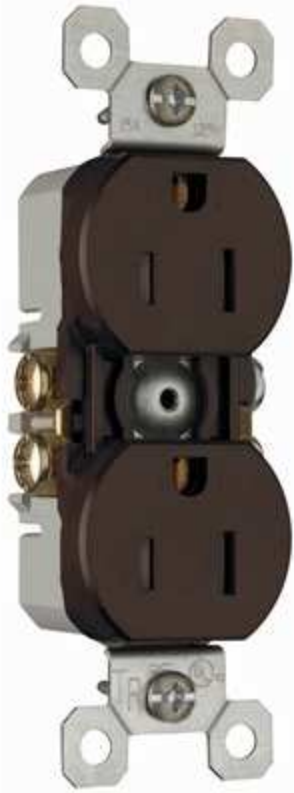

•



•



•



## product gallery

Representative images shown.

### AVAILABLE OPTIONS



TradeMaster Tamper-Resistant Receptacle



TradeMaster Tamper-Resistant Receptacle



TradeMaster Tamper-Resistant Receptacle




TradeMaster Tamper-Resistant Receptacle

- SPECIFICATIONS
- YOU MIGHT LIKE
- RESOURCES

## features & benefits

- Meets 2008 National Electrical Code Tamper-Resistant requirements.
- Protects children: patented shutter system helps prevent improper insertion of foreign objects.
- High-impact resistant thermoplastic construction.
- Extra-long strap.
- Quickloop wire looping aid.
- Long-term blade retention.
- Longer tri-drive screws for easier 12 AWG looping.
- Extra-large circuit break-off tabs.
- Side-access push wire release.
- Ultrasonic welding of face to back body.
- Side wire accepts #12 – #14 AWG solid wire.
- Push wire accepts #14 AWG solid only.
- Superior protection than traditional outlet caps or protection plates.
- Low profile face.
- Traditional contoured face (3232 models).
- Self-grounding models provide automatic ground clip.

## Top 5 Resources

-  [Tamper-Resistant Receptacles \(Brochure\)](#)

## specifications

### General Info

- Color: Brown
- Type: Tamper-Resistant

## Listing Agencies/Third Party Information

- CSA Listing Info: C22.2 No.42
- CSA Standard: Yes
- cU Lus: Yes
- Federal Spec: No
- UL Listing No: UL498
- UL Standard: Yes
- U N SPS C: 39121406

## Dimensions

- Depth (U S): 1"
- Height U S: 3.31"
- Width U S: 1.32"

## Technical Information

- Amps: 15 Amp
- Volts A C: 125

## Buy American Act Compliance

- Country of Origin: CHINA
- Buy American Act Status: No
- 

## you might like



### TradeMaster Tamper-Resistant Receptacle

885TR

[View Details](#)



### Duplex Receptacle Openings, One Gang, Brown

TP8

[View Details](#)



## **2000TR Series Tamper-Resistant Multioutlet System**

2000TR

[View Details](#)

**resources**

**BROCHURE**

 [Tamper-Resistant ReceptaclesPDF \(791.69kb\)](#)