


## Straight Blade Plugs & Connectors Miscellaneous Configurations


**IP20**  
Suitability



**3869**


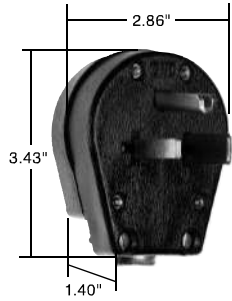


**3861**

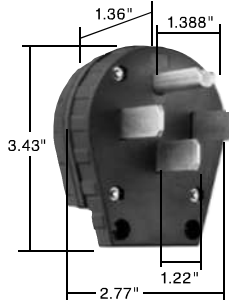


**3867**


Catalog Number	Rating		Description	Cord Diameter	NEMA Config. No.	3rd Party Compliance		
	A.	V.				UL	FSUL	CS
<b>2 Pole, 3 Wire Grounding</b>								
43379	30	125	Angled Plug, Yellow		5-30P			
43399	50	125	Angled Plug, Yellow		5-50P			
3869	30/50	250	Angled Plug, Black	.56"-1.1"	6-30P/6-50P		•	
<b>3 Pole, 3 Wire Non-Grounding</b>								
3861	30/50	125/250	Angled Plug, Black	.56"-1.1"	10-30P/10-50P		•	
9977	20	125/250	Plug, Nylon		10-20P		•	
7088	20	125/250	Connector, Armored		10-20R			
<b>3 Pole, 4 Wire Grounding</b>								
5746AN	30	125/250	Angled Plug, Yellow		14-30P		•	
5741AN	30	3ø, 250	Angled Plug, Yellow		15-30P		•	•
5745AN	50	125/250	Angled Plug, Yellow		14-50P			•
14629	60	125/250	Angled Plug, Yellow		14-60P			•
5751AN	50	3ø, 250	Angled Plug, Yellow		15-50P		•	•
5761AN	60	3ø, 250	Angled Plug, Yellow		15-60P		•	•
3867	30/50	125/250	Angled Plug, Black	.56"-1.1"	14-30P/14-50P		•	•
<b>4 Pole, 4 Wire Non-Grounding</b>								
7251DF	20	3øY, 120/208	Plug, Yellow	.365"-.775"	18-20P		•	•
8302AN	60	3øY, 120/208	Angled Plug, Yellow		18-60P		•	

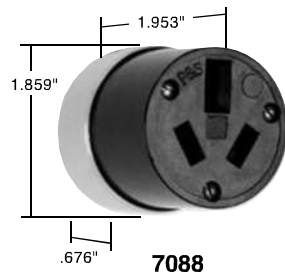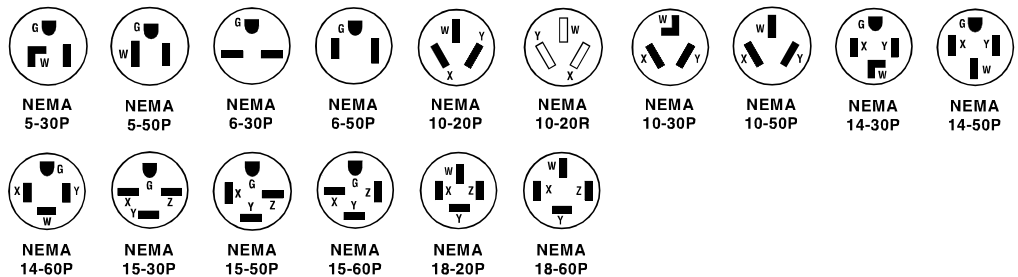

**7088**

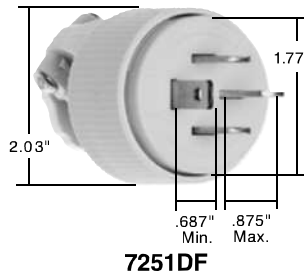


**7251DF**

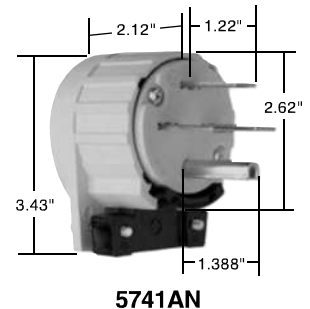

**5741AN**



**9977**

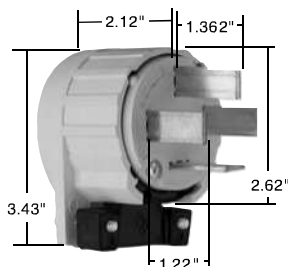

**8302AN**

All devices listed on this page conform to NEMA WD-1 and WD-6.