



Industrial Spec Grade Turnlok® Locking Devices

15 Amp NEMA L515



2 Pole, 3 Wire 15A, 125V




Catalog Number	Rating A. V.	Description/Color	Cord Diameter	NEMA Config. No.	3rd Party Compliance		
					UL498	FSUL WC596	CSA
Receptacles							
4710	15 125	Single Receptacle		L5-15R	•	•	•
IG4710	15 125	Single Receptacle, Orange, Isolated Ground		L5-15R	•	•	•
4700	15 125	Duplex Receptacle		L5-15R	•	•	•
IG4700	15 125	Duplex Receptacle, Orange, Isolated Ground		L5-15R	•	•	•
4792	15 125	Combination Straight Blade and Locking		5-15R and L5-15R	•		
Connectors IP20 Suitability							
PSL515C	15 125	Black Back, White Front Body	.230"-.720"	L5-15R	•	•	•
CRL515C	15 125	Yellow Back, White Front Body, Corrosion-Resistant	.230"-.720"	L5-15R	•	•	•
Plugs IP20 Suitability							
PSL515P	15 125	Black Back, White Front Body	.230"-.720"	L5-15P	•	•	•
CRL515P	15 125	Yellow Back, White Front Body, Corrosion-Resistant	.230"-.720"	L5-15P	•	•	•
Flanged Inlets & Outlets							
4716SS	15 125	Gray Inlet		L5-15P	•		•
4715SS	15 125	Gray Outlet		L5-15R	•		•
Straight Blade/Locking Adapters							
44859	15 125	High-Visibility Yellow		5-15R/L5-15P			

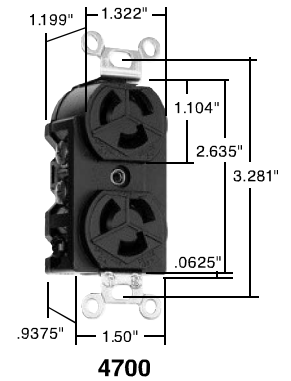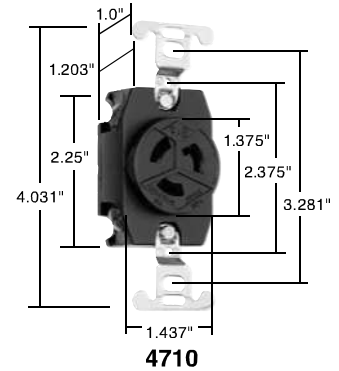


Reference Pages H-35 and H-36 for Accessories.

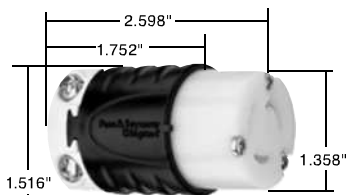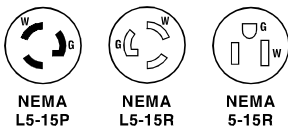


15A Connector

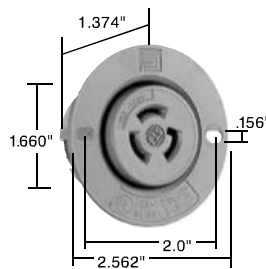


4715SS

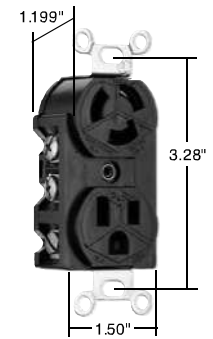

4792

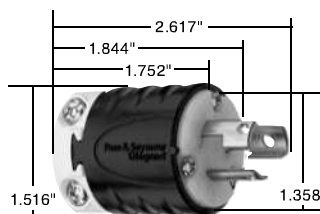

15A Plug

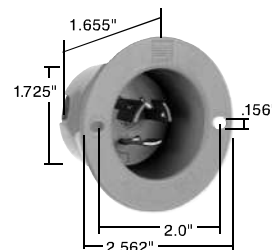

4716SS

All devices listed on this page conform to NEMA WD-1 and WD-6.