




designed to be better.

 Search

Specification Grade Surge Protective Duplex Receptacle, Ivory

5262ISP

Surge Protective Extra Heavy-Duty Duplex Receptacle offers increased transient protection, reliability and protection notification (Audible Alarm with LED Indicator). Back & Side Wire, 15amp 125volt, Ivory.

Submit Query


Where to buy

Submit Query

Like

Tweet

 
Email Print

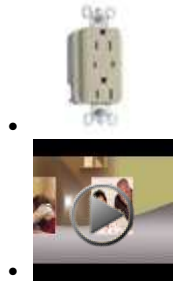

product gallery

Representative images shown.

AVAILABLE OPTIONS



Specification Grade Surge Protective Duplex Receptacle, White



Specification Grade Surge Protective Duplex Receptacle, Black



Specification Grade Surge Protective Duplex Receptacle, Blue



Specification Grade Surge Protective Duplex Receptacle, Gray



Specification Grade Surge Protective Duplex Receptacle, Light Almond



Specification Grade Surge Protective Duplex Receptacle, Red








Specification Grade Surge Protective Duplex Receptacle, Brown

- RELATED PRODUCTS
- SPECIFICATIONS
- YOU MIGHT LIKE
- RESOURCES

features & benefits

- **Solid-state LED monitor** has 25-year minimum life expectancy. A high visibility, wide-angle lens indicates protection is in place.
- **LED Indication:** Steady green = protected, Flashing re = not protected, OFF = no power to unit
- **Audible alarm alert** of MOV damage. Alarm able to be turned On/Off.
- **Wrap-around steel strap** for structural integrity. Auto-ground is standard, for easier installation.
- **Impact-resistant thermoplastic exterior** resists impacts and scrapes.
- **Triple-wipe, copper-alloy contacts** for superior, more dependable connection.
- **External screw-pressure-plate back and side wire terminals including ground with external back wire clamps (exclusive)** accept #14 - #10 AWG copper or copper-clad, solid or stranded conductors. External pressure plate feature allows two conductors to be terminated by a single screw.
- **Thermal protection in 3 modes. 3 17mm dual pack MOVs absorb up to 340 Joules** of excess energy in each leg (L-N, L-G, N-G) with 24,000 amp current handling capability for full, equal and symmetrical protection. Protection response time in less than one nanosecond.

Top 5 Resources

-  [Commercial & Industrial Products \(Brochure\)](#)
-  [Heavy Duty Surge Protective Receptacles, SF1304R1 \(Cutsheet\)](#)
-  [Surge Protective Devices \(Installation Instructions\)](#)

related products



Decorator Openings, One Gang, 302 Stainless Steel

SS26

[View Details](#)



Surge Protective Power Strip 7 Outlet, PC Gray

PS7

[View Details](#)

specifications

General Info

- Color: Ivory
- Type: Duplex
- Duty: Extra Heavy Duty
- Special Features: Audible Alarm with LED Monitor, Isolated Ground

Listing Agencies/Third Party Information

- CSA Listing Info: No
- CUL Listing No: No
- cU Lus: Yes
- cU Rus: No
- Federal Spec: Yes
- Fed Spec Number: WC596
- UL Listing No: No
- U N SPS C: 39121406
- U R: No

Dimensions

- Depth (U S): 1.225" (Behind Strap)
- Height U S: 3.82"
- Width U S: 1.750"

Technical Information

- Amps: 15 Amp
- Volts: 125V
- Volts A C: 125
- Grade Type: Specification

Buy American Act Compliance

- Country of Origin: CHINA
- Buy American Act Status: No
-

you might like



Panel TVSS Unit, Heavy Duty

1220TWH

[View Details](#)



Extra-Hard Use (EHU) Specification Grade Plug, Black & White

PS5266X

[View Details](#)

resources BROCHURE

 [Commercial & Industrial ProductsPDF \(3.52mb\)](#)

CUTSHEET

 [Heavy Duty Surge Protective Receptacles, SF1304R1PDF \(148.7kb\)](#)

INSTALLATION INSTRUCTIONS

 [Surge Protective DevicesPDF \(497.67kb\)](#)