



Straight Blade Receptacles Miscellaneous Configurations

Straight Blade Receptacles, 3 Wire, Specification Grade



Catalog Number	Rating A. V.	Description	NEMA Config. No.	3rd Party Compliance		
				UL	FSUL	CS
2 Pole, 3 Wire Grounding						
5762	15 277	Duplex Receptacle, Self-Grounding	7-15R	•		
PS5766X	15 277	Plug, Yellow	7-15P	•		•
7621	20 277	Single Receptacle	7-20R	•		
PS5866X	20 277	Plug, Yellow	7-20P			
3 Pole, 3 Wire Non-Grounding						
6810I	20 125/250	Receptacle, Ivory	10-20R	•		
6810	20 125/250	Receptacle, Black	10-20R	•		
9977	20 125/250	Plug, Nylon	10-20P			
7088	20 125/250	Connector, Armored	10-20R			

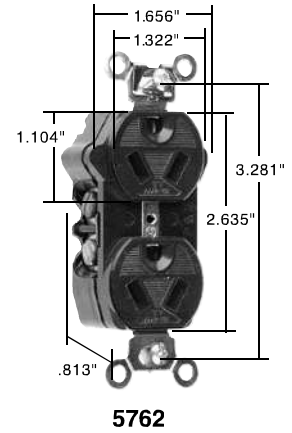


5762

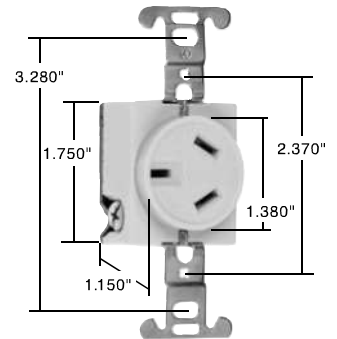


6810I

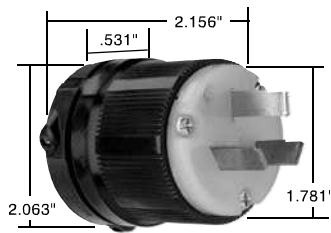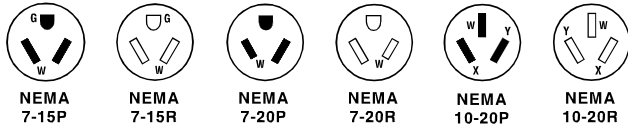

9977

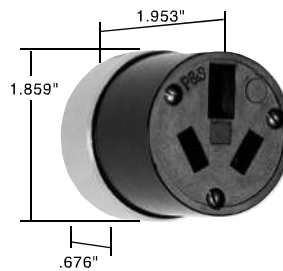

7088

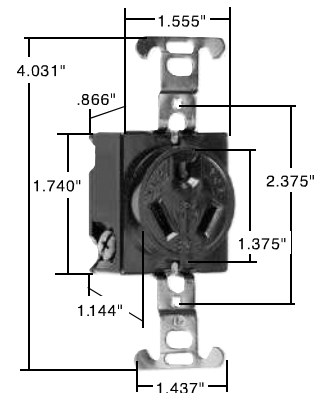

7621