

# Straight Blade Receptacles TradeMaster® Decorator Receptacles


15A, 125V

**Pass & Seymour**



Straight Blade Receptacles

Features	
<ul style="list-style-type: none"> <li>■ High impact-resistant thermoplastic construction.</li> <li>■ Extra-long strap.</li> <li>■ Quickloop wire looping aid.</li> <li>■ Long-term blade retention.</li> <li>■ Tri-drive screws.</li> <li>■ Extra-large circuit break-off tabs.</li> </ul>	<ul style="list-style-type: none"> <li>■ Side-access push wire release.</li> <li>■ Ultrasonic welding of face to back body.</li> <li>■ Side wire accepts #12 – #14 AWG solid.</li> <li>■ Push wire accepts #14 AWG solid only.</li> <li>■ Self-grounding models provide automatic ground clip.</li> </ul>

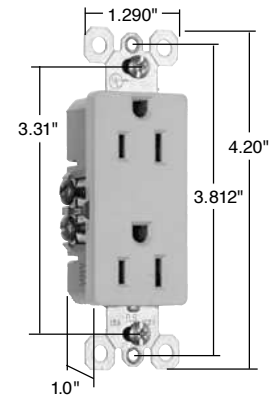


**8851**

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance	
				UL498	C22.2 42
<b>Decorator Duplex Receptacles</b>					
885I	15 125	Ivory	5-15R	•	•
885W	15 125	White	5-15R	•	•
885	15 125	Brown	5-15R	•	•
885BK	15 125	Black	5-15R	•	•
885LA	15 125	Light Almond	5-15R	•	•
<b>Self-Grounding Decorator Duplex Receptacles</b>					
885SI	15 125	Ivory	5-15R	•	•
885SW	15 125	White	5-15R	•	•
885SLA	15 125	Light Almond	5-15R	•	•

*For Configurable Solutions, see Page U-1.*

Features	
<ul style="list-style-type: none"> <li>■ Longer steel straps than competitive devices, still fits under a standard wall plate.</li> <li>■ High-impact thermoplastic face and back body eliminate cracks, breaks and callbacks.</li> <li>■ Ultrasonic welding of face to back body.</li> <li>■ Patented design provides better plug retention.</li> <li>■ External screw-pressure-plate back wire on all four terminal screws and ground screw eliminates wrapping.</li> </ul>	<ul style="list-style-type: none"> <li>■ Accepts #12 and #14 stranded and solid wire.</li> <li>■ Break-off tabs that are big enough to grab hold of – even if the contact screws are backed-out. Scored deeper, for fast, clean breaks every time.</li> <li>■ All four contact screws and the ground screw are backed-out.</li> <li>■ All screws are tri-drive.</li> </ul>

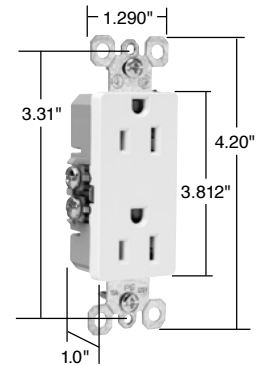

**TM885W**

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance
				UL498
<b>Decorator Duplex Receptacles with Pressure Plates</b>				
TM885I	15 125	Ivory	5-15R	•
TM885W	15 125	White	5-15R	•
TM885	15 125	Brown	5-15R	•
TM885GRY	15 125	Gray	5-15R	•
TM885BK	15 125	Black	5-15R	•
TM885LA	15 125	Light Almond	5-15R	•
<b>Decorator Duplex Receptacles with Pressure Plates Self-Grounding</b>				
TM885SI	15 125	Ivory	5-15R	•
TM885SW	15 125	White	5-15R	•
TM885SLA	15 125	Light Almond	5-15R	•
<b>Decorator Duplex Receptacles with Pressure Plates Bulk Pack of 150</b>				
TM885I150	15 125	Ivory	5-15R	•
TM885W150	15 125	White	5-15R	•
TM885LA150	15 125	Light Almond	5-15R	•

2 Pole, 3 Wire



NEMA  
5-15R

All devices listed on this page conform to NEMA WD-1 and WD-6.

TradeMaster® Receptacles