

8+PC9hPiA8YSBpZD0iY3RsMDVFTWFpbk5hdjFfY3RsMDJfcjB0Q29tbWVvY2IhbF9jdGwwM19ycHRDb21tZXJjaWFsU3VibWVudV9jdGwxMF9obFZpZXdlMaV



designed to be better.

 Search

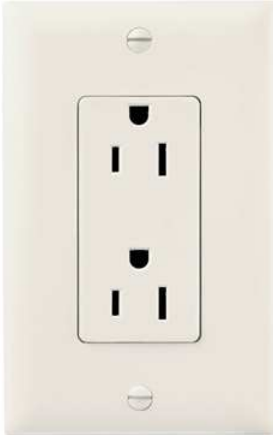
## TradeMaster Decorator Duplex Receptacle, Light Almond

885LA

Decorator Duplex Receptacle, 15amp 125volt, Side &amp; Speedwire, Light Almond

Where to buy 


0

Representative image shown.

### AVAILABLE OPTIONS



TradeMaster Decorator Duplex Receptacle, White



TradeMaster Decorator Duplex Receptacle, Black



TradeMaster Decorator Duplex Receptacle, Ivory

- SPECIFICATIONS
- YOU MIGHT LIKE

### features & benefits

- High impact-resistant thermoplastic construction.
- Extra-long strap.
- Quickloop wire looping aid.
- Long-term blade retention.
- Tri-drive screws.
- Extra-large circuit break-off tabs.
- Side-access push wire release.
- Ultrasonic welding of face to back body.
- Side wire accepts #12 - #14 AWG solid.
- Push wire accepts #14 AWG solid only.
- Self-grounding models provide automatic ground clip.

### specifications

#### General Info

- Color: Light Almond
- Number Of Poles: 2

- Number Of Wires: 3

#### Listing Agencies/Third Party Information

- CSA Listing Info: C22.2 No.42
- CSA Standard: Yes
- Federal Spec: No
- UL Listing No: UL498
- UL Standard: Yes
- U N SPS C: 39121704

#### Dimensions

- Depth (U S): 1"
- Height U S: 3.31"
- Width U S: 1.29"

#### Technical Information

- Amps: 15
- Volts: 125
- Volts A C: 125

#### Buy American Act Compliance

- Country of Origin: CHINA
- Buy American Act Status: No
- 

#### you might like



#### Plugmold Multi-Outlet Strips

[View Details](#)



#### Metal Raceway

[View Details](#)



#### CornerMate Cord Organizer

[View Details](#)