

nZSI+IDxhIGIkPSJjdGwwNV9NYWluTmF2MV9jdGwwMI9ycHROZXdJdGVtc19jdGwwNV9obE5ld0ltYWdlIiBocmVmPSIvb3J0cm9uaWNzL2NvcHBici9jbC




designed to be better.

Search

Screwless Decorator Openings, Metal Subplate, Four Gang, Light Almond

SW264LA
Screwless Wall plates 4gang Decorator Metal Subplate Light Almond

Submit Query Enter Postal Code Submit Query 0 [Email](#) [Print](#)

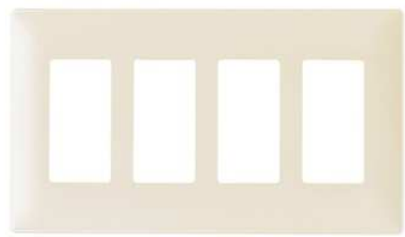

Representative image shown.

AVAILABLE OPTIONS



Screwless Decorator Openings, Metal Subplate, Four Gang, White



Screwless Decorator Openings, Metal Subplate, Four Gang, Brown



Screwless Decorator Openings, Metal Subplate, Four Gang, Black



Screwless Decorator Openings, Metal Subplate, Four Gang, Gray



Screwless Decorator Openings, Metal Subplate, Four Gang, Ivory

- SPECIFICATIONS
- RESOURCES

features & benefits

- Molded of .065" thick polycarbonate with matte finish.

- 2-piece plastic subplate made of polycarbonate ("SWP" Series only).
- Metal subplate made of .042" zinc-plated steel ("SW" Series only).
- Extra 1/8" width and height than Standard size plates.
- Available in Ivory, White, Brown, Gray, Black, and Light Almond.
- Oversized opening to accommodate all NEMA 26 decorator-style openings.

Top 5 Resources

-  Commercial & Industrial Products (Brochure)
-  Screwless Wall Plates (Brochure)

specifications

General Info

- Color: Light Almond
- Type: Screwless
- Style: Decorator

Listing Agencies/Third Party Information

- CSA Listing Info: No
- CUL Listing No: No
- cU Lus: Yes
- cU Rus: No
- Federal Spec: No
- UL Listing No: No
- U N SPS C: 39121704
- U R: No

Dimensions

- Height U S: 4.87"
- Width U S: 8.536"

Technical Information


- Material: Metal
- Capacity: 4-Gang

Buy American Act Compliance

- Country of Origin: UNITED STATES OF AMERICA
- Buy American Act Status: Buy American Act Compliant
-



resources BROCHURE

-  Commercial & Industrial ProductsPDF (3.52mb)
-  Screwless Wall PlatesPDF (749.69kb)