


**legrand®**  
Pass & Seymour

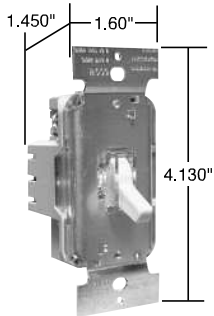

T600I  
TSC5I

## Residential Dimmers & Fan Speed Controls TradeMaster® Toggles



### Features

- Tough impact-resistant thermoplastic housing.
- Power-failure memory.
- Superior heat management: no time wasting break off tabs.
- Exclusive, screw-pressure-plate back wire terminals eliminates wire nuts.

Catalog Number		Description	Ratings	Color
Single Pole	Three-Way			
<b>600W Incandescent Toggle Dimmers</b>				
T600I* T600W* T600* T600LA*	T603I** T603W** T603** T603LA**	Non-Preset	120V 600W	Ivory White Brown Light Almond
<b>600W Incandescent – Lighted Toggle Dimmers*</b>				
T600LI T600LW T600LLA	T603LI T603LW T603LLA	Non-Preset	120V 600W	Ivory White Light Almond
<b>1000W Incandescent Toggle Dimmers</b>				
T1000I* T1000W* T1000* T1000LA*	T1003I** T1003W** T1003** T1003LA**	Non-Preset	120V 1000W	Ivory White Brown Light Almond
<b>1000W Incandescent – Lighted Toggle Dimmers**</b>				
T1000LI T1000LW T1000LLA	T1003LI T1003LW T1003LLA	Non-Preset	120V 1000W	Ivory White Light Almond
<b>600VA Low-Voltage Magnetic Toggle Dimmers*</b>				
TLV600I TLV600W TLV600LA	TLV603I TLV603W TLV603LA	Non-Preset	120V 600VA	Ivory White Light Almond
<b>1000VA Low-Voltage Magnetic Toggle Dimmers**</b>				
TLV1000I TLV1000W TLV1000LA	TLV1003I TLV1003W TLV1003LA	Non-Preset	120V 1000VA	Ivory White Light Almond
<b>Toggle Fan Speed Controls*</b>				
TSC5I TSC5W TSC5LA	—	Non-Preset, Adjustable Trim	120V 5A	Ivory White Light Almond

\* Available in VisionPak™ packaging, add "V" to Catalog Number. Example: T600LAV.

\*\* Available in boxed packaging only.

Max. Load Rating	Gang Reduction	
	2 Dimmers	3+ Dimmers
<b>De-Rating Chart</b>		
600W	500W	400W
1000W	700W	650W

Max. Load Rating	Gang Reduction	
	2 Controls	3+ Controls
<b>De-Rating Chart</b>		
5A	4A	3A