



TMHWLCC

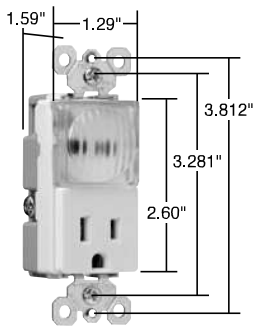

TMHWLECC



TM8HWLWCC

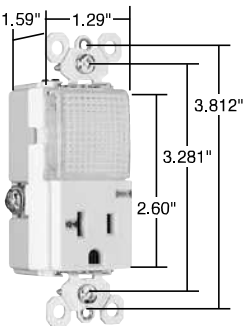

PS8HWLLA

Specialties Decorator Hallway Lights & Combination Devices

Features

- Impact-resistant face and body.
 - GE Lexan™ high impact-resistant lens.
 - External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
 - Ground screw position under the end of the strap minimizes the risk of contact.
 - Energy-efficient LED has average 20-year life expectancy; eliminates bulb replacement.
 - Sensor automatically turns light ON in the dark.
 - Increased light output for better illumination.
 - Light sensor for enhanced sensitivity.
- Tamper-Resistant Combination Version:**
- UL tested shutter mechanism for protection against improper object insertion per UL478.
 - Specially designed for increased protection of children in their homes.
 - Superior protection than traditional outlet “caps” or “protection plates.”

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	3rd Party Compliance
				UL1598
TradeMaster® Decorator Full Hallway Light with Light Sensor				
TMHWLCC	— 120	0.1328	Clear	•
Enhanced Decorator Full Hallway Light with Light Sensor				
TMHWLECC	— 120	1.079	Clear	•
Enhanced Decorator Full Hallway Light without Light Sensor				
TMHWLENSCC	— 120	1.113	Clear	•
Full Hallway Decorator Light for use with P&S Metal Louver Plates**				
TMHWLLOUVCC	— 120	0.0843	Clear	•

*FCD = Foot Candle Distance, 1 Lumen = 1 FCD. See page S-56 for more information.

**For Louver Plates, see Page Q-21.

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	NEMA Config. No.	3rd Party Compliance
					UL498
TradeMaster® Decorator Hallway Light & Single Receptacle					
TM8HWLICC	15 120/125	0.1442	Ivory	5-15R	•
TM8HWLWCC	15 120/125	0.1442	White	5-15R	•
TM8HWLBKCC	15 120/125	0.1442	Black	5-15R	•
TM8HWLCC	15 120/125	0.1442	Brown	5-15R	•
TM8HWLLACC	15 120/125	0.1442	Light Almond	5-15R	•
Specification Grade Enhanced Decorator Hallway Light & Single Receptacle					
PS8HWLI	20 120/125	0.2561	Ivory	5-20R	•
PS8HWLW	20 120/125	0.2561	White	5-20R	•
PS8HWLLA	20 120/125	0.2561	Light Almond	5-20R	•
TradeMaster® Enhanced Decorator Hallway Light & Tamper-Resistant Single Receptacle					
TM8HWLTRICC	15 125	0.2561	Ivory	5-15R	•
TM8HWLTRWCC	15 125	0.2561	White	5-15R	•
TM8HWLTRBKCC	15 125	0.2561	Black	5-15R	•
TM8HWLTRCC	15 125	0.2561	Brown	5-15R	•
TM8HWLTRLACC	15 125	0.2561	Light Almond	5-15R	•

*FCD = Foot Candle Distance. 1 Lumen = 1 FCD. See page S-56 for more information.

For complete line of Decorator Combination Devices, see Pages D-9 – D-12, D-20, D-24, D-33, and D-39.