

TM870STMLACC10

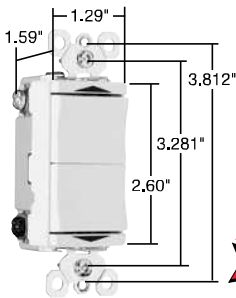
Switches Decorator & Specification Grade Momentary & Maintained Contact Switches

15A, 120 & 120/277VAC

Features

- Designer-style satin-finish rocker.
- High-impact resistant thermoplastic construction.
- External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
- Push wire #14 AWG.
- Narrow back body leaves more room for wires in the box.
- Extra-long, through-body strap eliminates floating installations and imperfect applications.
- Smooth, quiet paddle action.
- Easy-access green hex head ground screw.
- Tri-drive ground, terminal and mounting screws.

Catalog Number	Rating A. VAC	Color	3rd Party Compliance	
			UL20	C22.2 111
Single Pole Decorator Momentary Contact Switches				
TM870STMWCC10	15 120/277	White	•	•
TM870STMBKCC10	15 120/277	Black	•	•
TM870STMLACC10	15 120/277	Light Almond	•	•

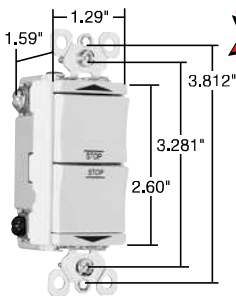
Momentary
Contact

NEW

Features

- Unique "Up/Down" switches match the look and feel of standard decorator switches.
- Impact-resistant face and body.
- Side and external screw-pressure-plate back wire accepts #12 and #14 AWG.
- All screws are tri-drive.
- Full wraparound heavy-gauge steel strap is plated for corrosion resistance and features lock-in tabs.
- Patent-pending split circuit tab — easily accessible, and can be reinstalled without a tool.

Catalog Number	Rating A. VAC	Color	3rd Party Compliance		
			cULus	UL20	UL508
Specification Grade Double Throw Momentary Contact Switches					
TM811DTMOI	15 120	Ivory	•	•	•
TM811DTMOW	15 120	White	•	•	•
TM811DTMOBK	15 120	Black	•	•	•
TM811DTMOLA	15 120	Light Almond	•	•	•
Specification Grade Double Throw Maintained Contact Switches					
TM811DTMAI	15 120	Ivory	•	•	•
TM811DTMAW	15 120	White	•	•	•
TM811DTMABK	15 120	Black	•	•	•
TM811DTMALA	15 120	Light Almond	•	•	•

Maintained
Contact

NEW